



ENGLISH

Datasheet

**RS Pro Midget Flange Filament Indicator Lamp, Clear, 6 V,
100 mA, 5000h**

RS Stock No: **105-001**

Product Details

RS Pro midget flange filament indicator lamp comes with clear lens and T1-3/4 incandescent bulbs. It has a voltage rating of 6 V and current rating of 100 mA. The lamp has 5000h life.

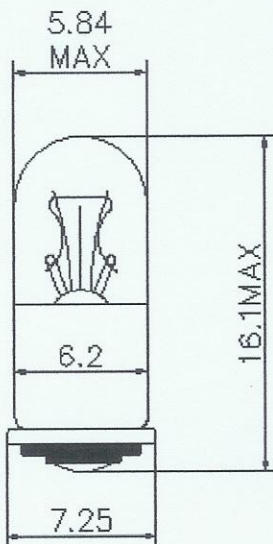
Features and Benefits

- Voltage rating of 6 V
- Current rating of 100 mA
- 5000 hours lifetime



Specifications:

Current Rating	100 mA
Diameter	5.84 mm
Lamp Base	Midget Flange
Lamp Size	T1 3/4
Length	16.1 mm
Lens Colour	Clear
Life Hours	5000 h
Luminosity	2.5 lm
Voltage Rating	6 V

RS Stock No.	105001	
<p><i>DRAWING - I</i></p>  <p style="text-align: right;">Unit : mm</p>		
1. Structure	Bulb Type	T1 3/4 Clear
	Bulb Diameter	Ø5.84Max.
	Length	16.1Max
	Base Type	M.F.
2. Design Characteristics	Voltage	6V
	Amperage	100mA±10%
	Filament Type	Vacuum type
	Luminous Flux	2.5Lm±20%
	Life Hours	5,000Hrs