




ENGL

Datasheet

Stock No. 106-5306

RS MINI POCKET TEMPERATURE/ HUMIDITY METER

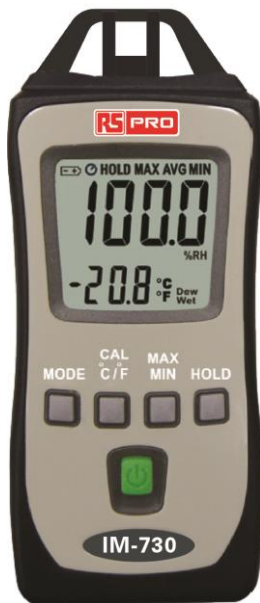

Feature:

- °C / °F unit selectable.
- Dual display of temperature and humidity.
- Simultaneously hold both temperature and humidity readings.
- Simultaneously hold both maximum and minimum and average readings (MAX/MIN/AVG).
- Auto-power off.
- Low battery Indication.
- Dew-Point and Wet-Bulb temperature measurement

Specifications:

- Display: Dual LCD display. The maximum value of 9999 (main display) and 999 (secondary display).
- Sampling Rate: 1 time per second.
- Measuring Range:
 - Temperature: -20.0°C ~50.0°C(-4.0°F~+122.0°F).
 - Humidity: 1.0% ~99%RH.(non-condensing).
- Accuracy:
 - Temperature: $\pm 1.0^{\circ}\text{C}$ ($\pm 1.8^{\circ}\text{F}$).
 - Humidity: $\pm 3.5\%$ for 20%~90% ; $\pm 5\%$ for 1%~19.9% and 90.1%~99%.
- Power Supply: 2 batteries 1.5V AAA MN2400 LR03 AM4.
- Battery life: About 50 hours.
- Dimension: 107 x 48 x 23 mm (L x W x H).
- Weight: About 80g with batteries installed.
- Accessories: Manual, batteries and carrying bag.