

1123684-7 ✓ ACTIVE



TE Internal #: 1123684-7

DC Jack Connectors, Board-to-Board, 10 Position, 2.5 mm [.098 in]
Centerline, Plug, 30 VDC, Right Angle, Printed Circuit Board, Power
& Signal

[View on TE.com >](#)

Connectors > PCB Connectors > Battery Connectors & Holders > DC Jack Connectors



Connector System: **Board-to-Board**

Number of Positions: **10**

Centerline (Pitch): **2.5 mm [.098 in]**

Connector & Housing Type: **Plug**

Operating Voltage: **30 VDC**

Features

Product Type Features

Connector System	Board-to-Board
Connector & Housing Type	Plug
Sealable	No
Connector & Contact Terminates To	Printed Circuit Board

Configuration Features

Number of Positions	10
PCB Mount Orientation	Right Angle

Electrical Characteristics

Operating Voltage	30 VDC
-------------------	--------

Contact Features

Contact Current Rating (Max)	6 A
------------------------------	-----

Mechanical Attachment

PCB Mount Retention	With
PCB Mount Retention Type	Locating Post



Connector Mounting Type	Board Mount
-------------------------	-------------

Housing Features

Centerline (Pitch)	2.5 mm [.098 in]
--------------------	------------------

Usage Conditions

Operating Temperature Range	-20 – 80 °C [-4 – 176 °F]
-----------------------------	---------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Packaging Features

Packaging Quantity	50
--------------------	----

Packaging Method	Tray
------------------	------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
------------------------------	-----------

EU ELV Directive 2000/53/EC	Compliant
-----------------------------	-----------

China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
---	---

EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2022 (223) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
--	---

Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
-----------------	--

Solder Process Capability	Wave solder capable to 265°C
---------------------------	------------------------------

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts




TE Part # 1123688-3
2.5 BATTERY REC ASSY 6P




TE Part # 1674231-1
2.5MM PITCH HIGH CURRENT BATTE

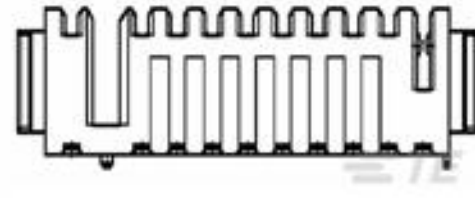

TE Part # 1-1123688-7
RECEPTACLE ASSY.10POS, 2.5MM PITCH BATTE



TE Part # 1123688-7
2.5 BATTERY CONN REC 10P

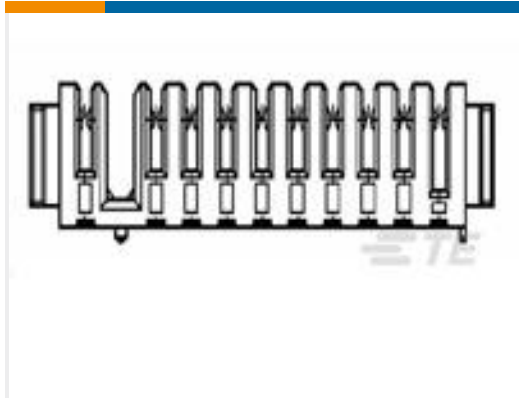

TE Part # 1565860-1
2.5MM PITCH BATTERY CONNECTOR,



TE Part # 1612964-4
2MM PITCH BATTERY REC. ASSY 10



TE Part # 1-1473776-7
2.5MM PITCH BATTERY REC ASSEMBLY SMT TYP




TE Part # 1746498-5
2.5MM PITCH BATTERY CONNECTOR 8P



TE Part # 1123738-7
2.5 BATTERY CONN PLUG 10P



TE Part # 1473539-7
2.5 BATTERY PLUG ASSY 10P

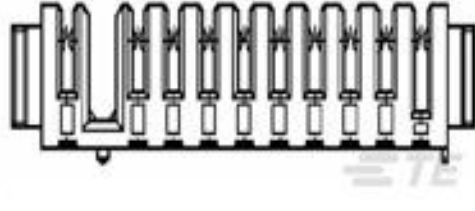


TE Part # 1473776-7
2.5MM BATTERY REC ASSEMBLY



TE Part # 1565596-1
PLUG ASSY FOR 2.5MM PITCH BATT



TE Part # 1674999-1
PLUG ASSY,2.5MM PITCH BATTERY



TE Part # 1717712-1
2.5MM PITCH BATTERY PLUG ASSY OFF-SET TY



TE Part # 1827622-2
2mm pitch Battery Rec. Assy 10Pos.

Customers Also Bought



TE Part #440055-6
2.0MM,HDR,6POS,R/A



TE Part #1-1734592-2
FPC CONN. 0.5MM PITCH B/C, 12P



TE Part #1775441-4
EMIX CONN., 1.5MM PITCH, RCPT, HSG, 4P



TE Part #2176070-7
3521 18R 1% 2W




TE Part #5-103634-5
06 MTE HDR SRRA LATCH.100CL LF



TE Part #5-104363-4
05 MTE HDR SRST LATCH .100CL




TE Part #1734290-1
IEEE 1394, RCPT, 6P, V/T, DIP, H 2.69

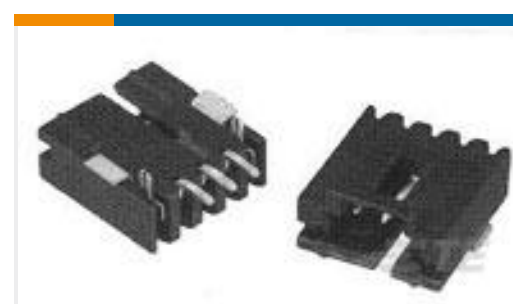

TE Part #5-147278-1
02 MTE HDR SRRA SFMNT .100CL



TE Part #4-794618-6
16P MICRO MNL ASSY R/A HDR LF

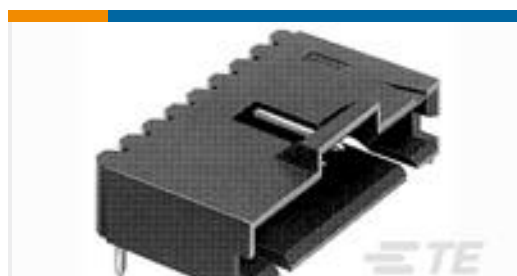

TE Part #5-103634-1
02 MTE HDR SRRA LATCH.100CL LF

Documents

Product Drawings

2.5 BATTERY CONN PLUG 10P STD

English

CAD Files

3D PDF

English

Customer View Model

[ENG_CVM_1123684-7_C.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_1123684-7_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_1123684-7_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

POWER_CONNECTORS_CATALOG_SEC09_LAPTOPS_PORTABLES

English

2_PIECE_POWER_CONNECTORS_qrg_4-1773458-1

English

Product Specifications

Product Specification

English



Product Environmental Compliance

Product Compliance

English

Product Compliance

English