


**DIN 975**

Standard withdrawn

**4.6 / 4.8**

At manufacturer's option

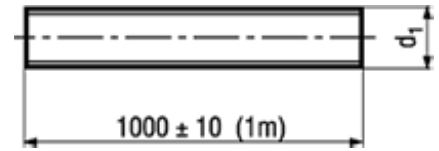

**BN 419**

**Threaded rod**

metric thread

**1 meter**

Steel 4.6 / 4.8

zinc plated blue

- Length: 1-3 meter
- Thread tolerances 6g / 8g for plain and 6h / 8h for zinc plated blue



Corresponding to DIN 976-1, type A

M7: not included in DIN 975

Article#	d <sub>1</sub>
1173200	M2
1173235	M2,5
1173251	M3
1173278	(M3,5)
1173286	M4
1173294	M5
1173308	M6
1173316	M7
1173324	M8
1173332	M10
1173340	M12
1173359	(M14)
1173367	M16
1173375	(M18)
1173383	M20
1173391	(M22)
1173405	M24
1173413	(M27)
1173421	M30
1155199	(M33)
1155202	M36
1157132	M42