

Datasheet

**Stock No: 121-7839, 121-7840,**

**RS Pro Sockets for Octal General Purpose Relay**




### **Specifications:**

- Comes with metal retaining clip and ID tag
- Suitable for 121-7828, 121-7829, 121-7830, 121-7831, 121-7832, 121-7834, 121-7835, 121-7836, 121-7837, 121-7838

<b>RS Stock No</b>	<b>121-7839</b>	<b>121-7840</b>
<b>Characteristics</b>		
Nominal Load	Current	12A
	Voltage	300V
Dielectric Strength	2500 V/S	
Max. Tightening Torque	1Nm	
Wire Size	20-14 AWG / 0.5-2.5mm <sup>2</sup>	
Ambient Temperature	-40~+85°C	
Unit Weight	50g	55g
Accessories	Metal Retaining Clip, ID tag	
Certification		

**Dimensions**

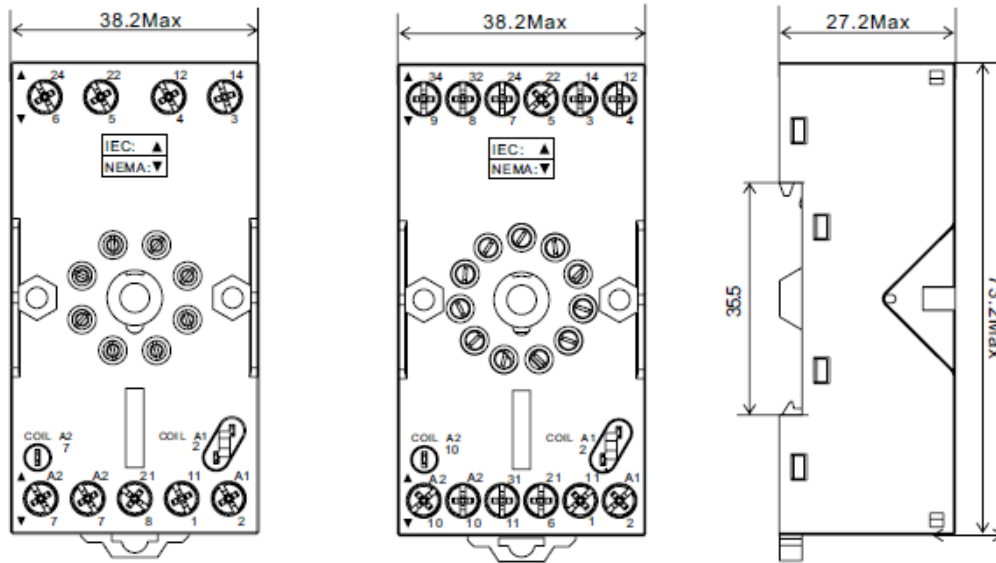

**Connection Diagram**

