




DIN 934

~ISO 4032

Standard withdrawn

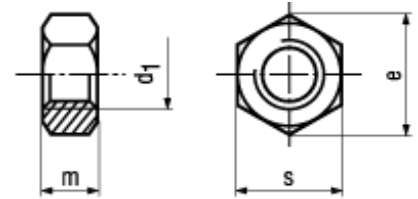

BN 629

Hex nuts ~0,8d

Stainless steel A4

- ~UNI 5588
- ~ČSN 021401

[3D Cadenas](#)

The commercial quality is class A2-70 / A4-70 (tensile strength 700 N/mm²) for M5-M24.

Article#	d ₁	e min.	s	m max.
3646085	M1,2	3,28	3	1
3646086	M1,4	3,28	3	1,2
1576240	M1,6	3,41	3,2	1,3
1348418	M2	4,32	4	1,6
1348426	M2,5	5,45	5	2
1576259	(M2,6)	5,45	5	2
1241613	M3	6,01	5,5	2,4
1241621	(M3,5)	6,58	6	2,8
1241648	M4	7,66	7	3,2
1241656	M5	8,79	8	4
1241664	M6	11,05	10	5
1241672	M8	14,38	13	6,5
1241680	M10	18,9	17	8
1241699	M12	21,1	19	10
1241702	(M14)	24,49	22	11
1241710	M16	26,75	24	13
1241729	(M18)	29,56	27	15
1241737	M20	32,95	30	16
1241745	(M22)	35,03	32	18
1241753	M24	39,55	36	19
1241761	(M27)	45,2	41	22
1241788	M30	50,85	46	24
1421816	(M33)	55,37	50	26
1421824	M36	60,79	55	29
1750194	(M39)	66,44	60	31
3145504	M42	71,3	65	34