

FEATURES

- A highly visible backlit LCD display
- Ergonomic and fast heating solder gun
- Features built-in data memory which stores up to 3 frequently used temperatures.
- Fast heat recovery
- Auto-sleep and wake
- System lock
- Tip calibration
- ESD safe
- Durable casing

RS PRO Soldering Station 60W, 220 → 240V

RS Stock No.: 124-4132



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From the trusted RS PRO brand, this smart soldering station has an LCD display screen for confidence and control in your soldering application. The station is supplied with a soldering gun that features a high-end alumina ceramic heating element providing you with fast heat recovery. It also features an easily adjustable temperature control dial, ensuring this high-performance smart soldering station is dependable and easy-to-use.

General Specifications

Plug type	Type F - Schuko plug, Type G - British 3-pin
Tasks supported	Soldering
Auto-sleep mode	Support
Applications	Engineers, Electricians, Metalworkers, jewellers, Home inventors

Electrical Specifications

Wattage	60W
Input Voltage	220 to 240
Output Power	60W
Number Of Outputs	2 (Iron and USB Output)
Display Type	LCD

Mechanical Specifications

Depth	180mm
Height	106mm
Width	150mm
Weight	1.75kg
Heater	High end alumina ceramic heating element

Operation Environment Specifications

Soldering Tip Temperature	480°C
Maximum Operating Temperature	480°C
Minimum Operating Temperature	200°C

Approvals

Compliance/Certifications	CE, ESD Standards, RoHS
----------------------------------	-------------------------




Soldering Tip: Conical






G

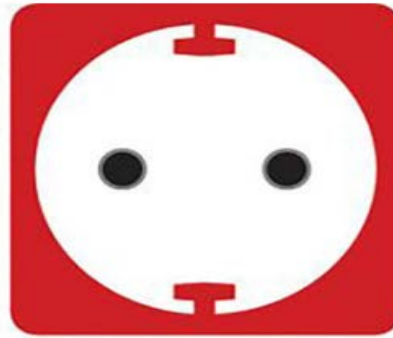


 

 

 

 

 

 
F

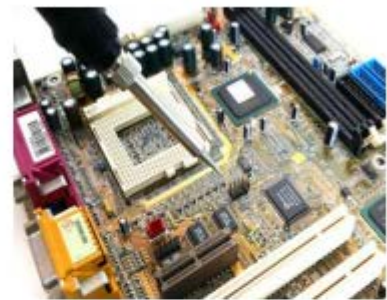

60 W Soldering iron



Replacement Accessories:

	Description	Type	Size	Tip Dimensions (mm)
7998973 	Soldering Tip, Chisel, 0.094 in/2.4 mm	Chisel	0.094" (2.4 mm)	
7998976 	Soldering Tip, Conical,	Conical	0.008" (0.2 mm)	
7998979 	Soldering Tip, Chisel, 0.047 in/1.2 mm	Chisel	0.047" (1.2 mm)	
7998982 	Soldering Tip, Chisel, 0.126 in/3.2 mm	Chisel	0.126" (3.2 mm)	
7998985 	Soldering Tip, Chisel, 0.031 in/0.8 mm	Chisel	0.031" (0.8 mm)	
7998989 	Soldering Tip, Sloped, 0.08 in/2 mm	Sloped	0.08" (2 mm)	

Stock Number	Description
771-9576	Soldering Iron Holder
136-8299	Solder Tip Cleaner
818-3207	Lead Free Tip Tinner