


LED Downlights

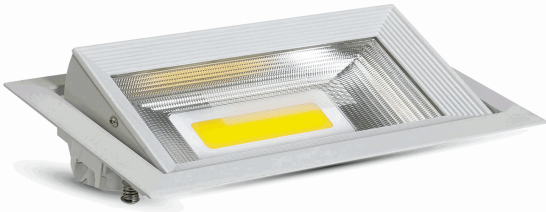

VT-2930

HIGHLIGHTS :

WATTS



30

LUMINOUS



2450

EQ. WATTS



NA

BEAM ANGLE



99

Item No	: VT-2930
SKU Code	: 1289
Watts	: 30
Voltage	: AC:220-264V, 50/60Hz
Lumen(lm)	: 2450
Color Temperature	: 6000K
Beam Angle	: 99
PF	: >0.9
LED Chip Type	: COB
CRI	: >80
Energy rating label	: A+
Certification	: EMC,LVD,ROHS
IP Rating Protection Class	: IP20

Body type	: Die Casting Material
Dimmable	: No
Life Time	: 20,000 HOURS
Operation Temperature	: -20~45'C
EAN code	: 3800157619646
Packing details	: 20
Unit cbm	: 0

PRODUCT FEATURES

- Innumerable styles & Elegant appearance
- Non-Flickering
- No UV Radiation
- Premium Quality Power Driver with lowest power factor saver & high RA
- Varied finishes with strong die cast Aluminium body
- Residences, Showrooms, Hotels & Boutiques etc.

[CLICK HERE](#)
FOR OTHER RELATED CERTIFICATES 