

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300550002](#)  
**Status:** **Active**  
**Overview:** Brad Industrial Ethernet Solutions  
**Description:** Brad RJ-Lnxx Industrial Ethernet Receptacle, Female (Straight) to Male (Straight) Front Panel Mount, 10Base T, Solder PCB and Cable Termination, 0.305m (1.0') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Receptacles
Series	<a href="#">130055</a>
IP Rating	IP67
Overview	<a href="#">Brad Industrial Ethernet Solutions</a>
Product Name	Brad, RJ-Lnxx
Type	Adapter
UPC	78678844697

**Physical**

Coupling Type	External Thread
Gender	Male
Keyway	None
Length	0.305m
Material - Component	ABS
Mounting Thread Size	1" - 14 UNC
Net Weight	35.273/g
Orientation	Straight
Panel Mount	Front
Poles	N/A
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	N/A

**Electrical**


Current - Maximum per Contact	1.5A
Voltage - Maximum	125V DC

**Material Info**

Engineering Number	ENSP1F5C305
--------------------	-------------

**Reference - Drawing Numbers**

Sales Drawing	SD-130055-002-001
---------------	-------------------

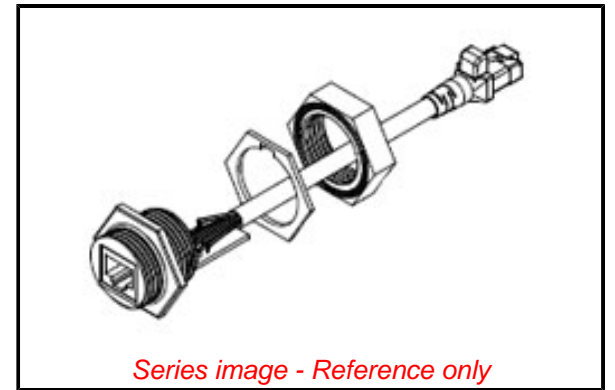

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT\_CE -

Declaration of

Conformity

**China RoHS**

Green Image

Not Relevant

Not Contained

CER\_4000380967\_00\_000.pdf

**Search Parts in this Series**

[130055 Series](#)