


ROLINE DisplayPort v1.4 Cable (AOC), M/M, 15 m

Product No.	14.01.3491
Manufacturer	ROLINE
Manufacturer No.	14.01.3491
EAN (single piece)	7630049627222

roline
Designed for Professionals

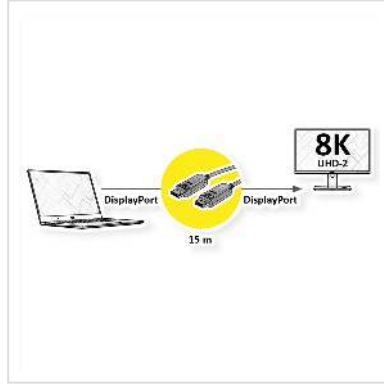

With our UHD (7680x4320 @60Hz) capable DisplayPort fiber optic cable you have the possibility to connect up to 15m between your devices. The active cable (AOC) does not require a separate power supply and is particularly suitable for installation in the cable duct due to its small diameter.

- Total length of the end device distance (e. g. from notebook/laptop to beamer or PC to monitor): 15 meters

Hardware solution, no software required

- No external power supply required; the cable contains a copper fibre for power supply
- Small connector and cable dimensions; the cable has a smaller diameter than comparable cables made of pure copper due to the glass fibres.
- The practical plug design prevents the cable from slipping out of the DisplayPort socket.
- Compliant DP v1.4 (max. 7680 x 4320 @60Hz)

Technical specifications

Manufacturer	ROLINE
Product group	Audio / video cable
Product type	DisplayPort extension
Colour	black

Length	15 m
Transfer quality	DisplayPort v1.4
Max. resolution	7680 x 4320 @60Hz (8K, UHD-2)
Side 1 Connector Type	DisplayPort
Side 1 Connector Gender	Male
Side 2 Connector Type	DisplayPort
Side 2 Connector Gender	Male
Weight	510 g
Height of packaging (single piece)	70 mm
Width of packaging (single piece)	170 mm
Depth of packaging (single piece)	180 mm
Package weight (single piece)	0.3 kg