

# Datasheet

# RS PRO Sockets

Stock No: 144-1609 & 144-1610



10/16 AMPS 300 VOLTS




Characteristics				
Type			144-1610	144-1609
Nominal load	Current	A	16	10
	Voltage	V	300	
Dielectric strength	Between coil and contact	V/min	4000	
	Between contacts	V/min	2500	
Max. tightening torque		Nm	1.0	
Wire size		AWG/mm <sup>2</sup>	20-14/0.5-2.5	
Ambient temperature		°C	-45~85	
Unit weight		g	22	27

Relay, accessories selection table						
Socket	Plastic clip	Metal clip	ID tag	Module	DIN rail	Bus jumper
144-1610	(included in socket)	-	-	-	PFP	SR08C
144-1609						

## Dimensions (mm)

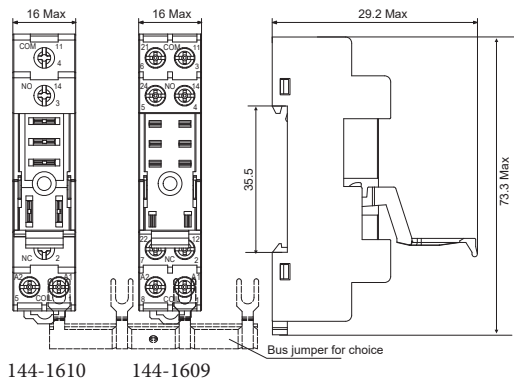

## Connection Diagrams

