

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1451300510](#)
Status: **Active**
Overview: Nano-Fit Power Connectors
Description: Nano-Fit-to-Nano-Fit Off-the-Shelf (OTS) Cable Assembly, Single Row, Matte Tin (Sn) Plating, 1.0m Length, 5 Circuits, Black

Documents:

| | |
|--------------------------------|--|
| 3D Model | Datasheet (PDF) |
| 3D Model (PDF) | RoHS Certificate of Compliance (PDF) |
| Drawing (PDF) | |

General

| | |
|------------------------|---|
| Product Family | Cable Assemblies |
| Series | 145130 |
| Application | Power, Wire-to-Board |
| Assembly Configuration | Dual Ended Connectors |
| Connector to Connector | Nano-Fit-to-Nano-Fit |
| Overmolded | No |
| Overview | Nano-Fit Power Connectors |
| Product Name | Nano-Fit |
| Type | Discrete Wire Assembly |
| UPC | 191130118922 |

Physical

| | |
|--------------------------------|--------------------------|
| Cable Length | 1.0m |
| Circuits (Loaded) | 5 |
| Color - Resin | Black |
| Gender | Female-Female |
| Lock to Mating Part | Yes |
| Material - Metal | High Conductivity Copper |
| Material - Plating Mating | Matte Tin |
| Material - Plating Termination | Matte Tin |
| Material - Resin | Nylon |
| Net Weight | 36.460/g |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Pitch - Mating Interface | 2.50mm |
| Plating min - Mating | 2.540µm |
| Plating min - Termination | 2.540µm |
| Single Ended | No |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 1.57mm |
| Wire Size AWG | 20 |
| Wire/Cable Type | UL 1061 |


Electrical

| | |
|-------------------------------|---------------|
| Current - Maximum per Contact | 8.0A |
| Voltage - Maximum | 250V AC (RMS) |

Material Info

Reference - Drawing Numbers

| | |
|---------------|----------------|
| Sales Drawing | 4000095320-000 |
|---------------|----------------|

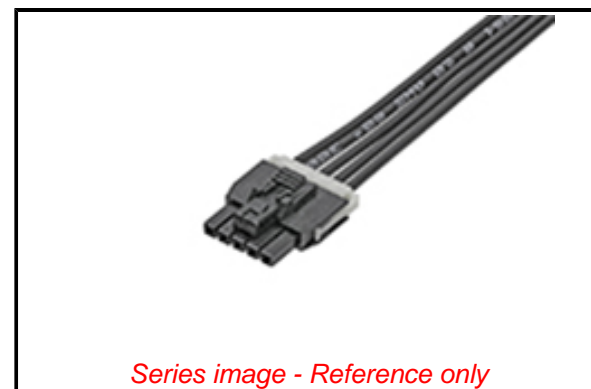

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[145130 Series](#)

Mates With

Nano-Fit Vertical Through Hole Headers
[1053091105](#) , [1053111105](#) . Nano-Fit Right-Angle Through Hole Headers [1053131105](#) .
 Nano-Fit Vertical SMT Headers [1054311105](#) .
 Nano-Fit Right-Angle SMT Headers
[1054301105](#) . Nano-Fit Plug Housing
[2002771105](#) , [2002771205](#)