




LED Industry A60 E27 7.5W (67W) 930lm 840 100V-260V AC/DC

Article number 145632

BAI LED Industry GLS E27 100V-260V AC/DC 7.5W (67W) 930lm 4000K Opal 180° 60x110mm 120V 130V 230V 240V 50/60Hz LED-lamp

Industrial lamps with a special voltage range and frequency of 50/60Hz. Ideally suited for use in industrial applications, factories, workshops, shipping, offshore, defense, railways, etc.). Ambient temperature range: -20°C to +40°C.

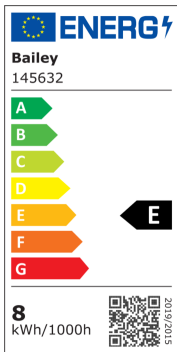

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	145632
Brand	Bailey
Productseries	Ecoplus LED
Product type	Industry

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG1
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	25000
Weighted energy consumption in 1000 hours [kWh]	7.5
Min. number of switching cycles	50000
Energy efficiency class	E
Lamp designation	Other
Degree of protection (IP)	IP20
Length [mm]	110
Diameter [mm]	60
Dimmable	No
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	180 - 180
Colour housing	White
Colour temperature [K]	4000 - 4000
Colour	White
Socket	E27
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Type of glass/cover	Opal
Filament lamp	No
Lamp shape	Other
Colour rendering index CRI	80-89
Luminous intensity [cd]	138
Lamp efficacy [lm/W]	124
Luminous flux [lm]	930 - 930
Voltage type	AC/DC
Lamp power [W]	7.5 - 7.5
Power factor	0.72
Nominal current [mA]	46 - 46
Nominal voltage [V]	100 - 260

Predecessor



80100040694

LED A60 E27
100V-250V AC/DC 9W
(65W) 890lm 840