


LED S14s 30X500 DIM 7W (50W) 640lm 827 Opal

Article number 145653

BAI LED S14s 30X500mm 7W (50W) 640lm 2700K Dimmable Opal 15000h LED-Lamp

Typical applications include bathrooms, mirrors, alcoves and kitchens. Ambient temperature: -10°C to +40°C.

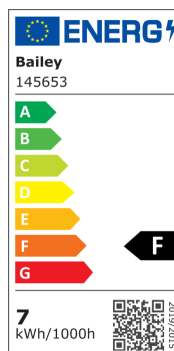

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	145653
Brand	Bailey
Productseries	BaiLinear LED
Product type	S14s

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG1
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	7
Min. number of switching cycles	15000
Energy efficiency class	F
Lamp designation	Other
Degree of protection (IP)	IP20
Length [mm]	500
Diameter [mm]	30
Dimmable	Yes
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	200 - 200
Colour housing	White
Colour temperature [K]	2700 - 2700
Colour	White
Socket	S14s
Colour of light according to EN 12464-1	Warm white <3300 K
Type of glass/cover	Opal
Filament lamp	No
Lamp shape	Tube, double-ended
Colour rendering index CRI	80-89
Lamp efficacy [lm/W]	91
Luminous flux [lm]	640 - 640
Voltage type	AC
Lamp power [W]	7 - 7
Power factor	0.9
Nominal current [mA]	33 - 33
Nominal voltage [V]	220 - 240

Alternative articles



144931

LED S14s 30X500 DIM
9W (45W) 550lm 827
Opal



145125



80100241748