


LED Spot R111/ES111 G53 12V DIM 9W (75W) 620lm 927 24D Bridge

Article number 145703

BAI LED Spot AR111/ES111 G53 12V 9W (75W) 620lm Dimmable 2700K CRI90 24° Anti-Glare bridge 66x111mm LED-Lamp

This R111/ES111 spot, with it's Anti-Glare bridge, replaces almost all halogen versions with a G53 lamp base and is available in 24 and 40 degrees. Ambient temperature range -20° C to 40°C.

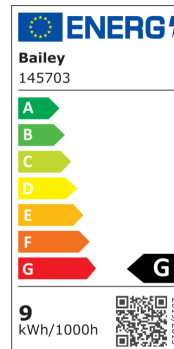

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	145703
Brand	Bailey
Productseries	BaiSpot LED LV
Product type	R111 Bridge

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG1
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	9
Min. number of switching cycles	30000
Energy efficiency class	G
Lamp designation	Other
Degree of protection (IP)	IP20
Length [mm]	66
Diameter [mm]	111
Dimmable	Yes
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	24 - 24
Colour housing	Black
Colour temperature [K]	2700 - 2700
Colour	White
Socket	G53
Colour of light according to EN 12464-1	Warm white <3300 K
Type of glass/cover	None
Filament lamp	No
Lamp shape	Reflector
Colour rendering index CRI	90-100
Luminous intensity [cd]	1240
Lamp efficacy [lm/W]	68
Luminous flux [lm]	620 - 620
Voltage type	AC/DC
Lamp power [W]	9 - 9
Power factor	0.9
Nominal current [mA]	880 - 880
Nominal voltage [V]	12 - 12

Alternative articles



143849

LED WarmDim AR111
G53 12V 9W 25D
927-918

145704

LED Spot R111/ES111
G53 12V DIM 9W
(75W) 620lm 927 40D
Bridge