


LED Ecoplus Night Sensor A60 E27 9W (60W) 820lm 827

Article number 145743

BAI Ecoplus LED Sensor GLS E27 9W (60W) 820lm 2700K Opal 230V-240V 200°
60x108mm Day / Night Lux Sensor LED-lamp

LED lamp with a day/night sensor. The lamp has a sensor that reacts to the light (not on artificial light). At dusk (< 15 lux), the lamp switches on and as soon as the light reappears, the lamp goes into sleep mode. You can therefore just leave the lamp "on" and never have to think again "would I have left the lamps on"? This makes this LED lamp even more energy efficient and sustainable than it already is.

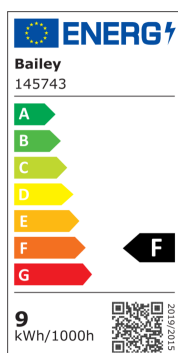

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	145743
Brand	Bailey
Productseries	Ecoplus LED
Product type	A60 Sensor

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG0
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	20000
Weighted energy consumption in 1000 hours [kWh]	9
Min. number of switching cycles	10000
Energy efficiency class	F
Lamp designation	A-type
Degree of protection (IP)	IP20
Length [mm]	108
Diameter [mm]	60
Dimmable	No
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	200 - 200
Colour housing	White
Colour temperature [K]	2700 - 2700
Colour	White
Socket	E27
Colour of light according to EN 12464-1	Warm white <3300 K
Type of glass/cover	Opal
Filament lamp	No
Lamp shape	Pear-shape
Colour rendering index CRI	80-89
Lamp efficacy [lm/W]	91
Luminous flux [lm]	820 - 820
Voltage type	AC
Lamp power [W]	9 - 9
Power factor	0.5
Nominal current [mA]	73 - 73
Nominal voltage [V]	220 - 240