




LED Ecobasic DimStick T45 E27 14W (100W) 1521lm 840

Article number 145766

BAI LED Ecobasic DimStick T45 E27 14W (100W) 1521lm 4000K Dimmable LED-lamp

Because these low-budget lamps are very durable due to their low consumption and long lifespan, they are both ECOlogical and ECONomic. This version of the Ecobasic is dimmable. Use the correct LED dimmer. For example the Bailey WW15031 LED Wall Dimmer. Ambient temperature range: -10°C to +40°C.

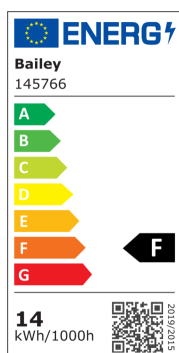

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	145766
Brand	Bailey
Productseries	Ecobasic LED stick
Product type	DimStick

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG1
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	14
Min. number of switching cycles	15000
Energy efficiency class	F
Lamp designation	Other
Energy Efficiency Index (EEI)	0.104
Degree of protection (IP)	IP20
Length [mm]	132
Diameter [mm]	45
Dimmable	Yes
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	360 - 360
Colour housing	White
Colour temperature [K]	4000 - 4000
Colour	White
Socket	E27
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Type of glass/cover	Opal
Filament lamp	No
Lamp shape	Tube, single-ended
Colour rendering index CRI	80-89
Lamp efficacy [lm/W]	110
Luminous flux [lm]	1521 - 1521
Voltage type	AC
Lamp power [W]	14 - 14
Power factor	0.9
Nominal current [mA]	62 - 62
Nominal voltage [V]	220 - 240

Alternative articles



145765

LED Ecobasic
DimStick T45 E27 14W
(96W) 1450lm 830