
 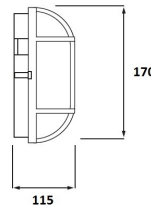


RoBust Bulkhead E27 Oval S Grey IP44 Max 60W

Article number 145969

BAI Bulkhead RoBust E27 Oval S Grey IP44 IK06 Outdoor Max 60W CLII
170x125x115mm Two cable entries Bulleye / Bullseye

The nostalgic lamp is back from never having been away. Tis ageless bulkhead, bulleye, bully as it is often called is made with a grey housing. Since it is rated IP44 this timeless fixture can both be used indoor and outdoor. It can both be mounted on wall and ceiling. The prismatic tempered glass is protected by a metal basket. The RoBust is supplied without a light source (Max 60W incandescent bulb) and without a cable, but the RoBust has a cable entry on both sides of the fixture.



General ETIM properties


ETIM group	Luminaires
ETIM class	Ceiling-/wall luminaire
Name	145969
Brand	Bailey
Productseries	BaiLum ceiling/wall
Product type	RoBust Bulkhead

ETIM specifications

Suitable for wall mounting	Yes
Suitable for suspended mounting	No
Suitable for ceiling mounting	Yes
Suitable for built-in mounting	No
Suitable for surface mounting	Yes
Suitable for light line configuration	No
Suitable for workplace according to EN 12464-1	No
Lamp type	LED exchangeable
With light source	No
Suitable for number of lamps	1
Lamp holder	E27
Material housing	Plastic
Surface protection housing	Untreated
Colour housing	Grey
Material cover	Glass structured
Type of grid	None
Voltage type	AC
Nominal voltage [V]	230 - 230
Type of control gear	Not required
With control gear	No
Exchangeable control gear	No
Dimming 0-10 V	No
Dimming 1-10 V	No
Dimming DALI-2	No
Dimming DALI	No
Dimming DMX	No
Dimming DSI	No
Dimming potentiometer (integrated)	No
Dimming GPRS	No
Dimming LineSwitch	No
Dimming manufacturer's proprietary system	No
Dimming mains voltage modulation	No
Dimming phase cut-off	No
Dimming phase cut-on	No
Dimming programmable	No
Dimming RF	No
Dimming Sine Wave Reduction	No
Dimming Touch and Dim	No
Dimming Zigbee	No
Dimming with push-button	No
Dimming depending on control gear	No
No dim function	Yes
Light distributor	Reflector
Light sharing	Symmetric
Beam angle	Extreme wide beam >80°
Light outlet	Direct
Degree of protection (IP)	IP44
Degree of protection (NEMA)	Other
Impact strength	IK06

Protection class	II
Luminaire with limited surface temperature, sign "D"	No
Suitable for emergency lighting	No
Emergency power supply integrated	No
With movement sensor	No
With light sensor	No
Covering of the luminaire with thermally insulating material possible	No
With air slots	No
Filament test according to IEC 60695-2-11	None
Suitable for lamp power [W]	60 - 60
Max. system power [W]	60
Constant light output (CLO)	No
Width [mm]	125
Height/depth [mm]	115
Length [mm]	170
Type of wiring	Suitable for through wiring
Number of poles	2
Conductor cross section [mm ²]	1.5
Connection type	Screwed terminal
Colour temperature adjustable	No
Luminous flux adjustable	No
Beam angle adjustable	No
Operation by Bluetooth	No
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No

Alternative articles

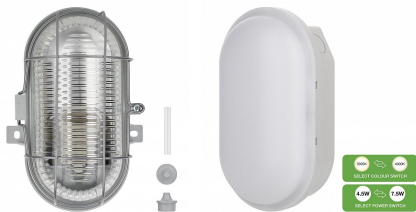

145970

RoBust Bulkhead E27
Oval L Grey IP44 Max
100W

146041

LED Bulkhead Switch
4.5W-7.5W 420-750lm
830-840 Oval Grey