
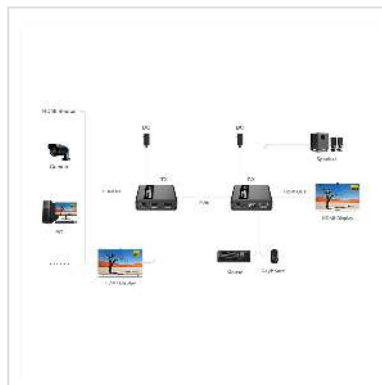


VALUE KVM Extender over Cat.6/6A, HDMI, max. 70m

Product No. 14.99.3042
Manufacturer VALUE
Manufacturer No. 14.99.3042
EAN (single piece) 7630049621268

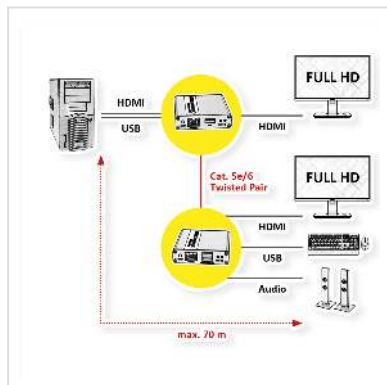

KVM extension over up to 70 m through the Cat.6/6A connection

- Supports HDMI with high resolution video up to 1920 x 1080 @ 60Hz (Full HD)
- Supports USB PC or KVM switch
- Ideal for professional video applications
- HDCP-compliant
- Supports EDID-Passthrough
- No drivers needed or software required
- Stable, metal housing
- Power supplied
- Receiver (RX) unit connectors: Monitor: 1x HDMI; 1x RJ-45 jack, 2x USB type A jack, 1x 3.5mm audio jack
- Transmitter (TX) unit connectors: Monitor: 2x HDMI; 1x RJ-45 jack, 1x USB type A jack

Technical specifications

Manufacturer	VALUE
Product group	KVM (IP) extensions
Product type	KVM-Extender, HDMI
Colour	black
Scope of delivery	Transmitter unit, receiver unit, 2x power supply, manual
Max. distance	70 m
PC/Switch: monitor connection	HDMI

PC/Switch: mouse/keyboard connection	USB
Remote Console: Monitor connection	HDMI
Remote Console: Mouse/Keyboard connection	USB
Max. distance local- remote unit	70 m
Max. resolution (nominal)	1920 x 1080 (max.)
Material (casing)	metal
Dimensions (HxWxD)	19 x 85 x 75 mm
Power supply output	DC 5V, 2A
Height	19 mm
Width	85 mm
Depth	75 mm
Height of packaging (single piece)	80 mm
Width of packaging (single piece)	150 mm
Depth of packaging (single piece)	200 mm
Package weight (single piece)	0.6 kg