

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1501811016](#)
Status: **Active**
Overview: [EconoLatch Wire-to-Wire Interconnects](#)
Description: [EconoLatch Female Terminal, 16-18 AWG, Tin \(Sn\) Plated, Reel](#)

Documents:

Drawing (PDF)	Packaging Specification PK-150180-001-000 (PDF)
Product Specification 1501760001-PS-000 (PDF)	Test Summary 1501760001-TS-000 (PDF)
Application Specification 1501760001-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Terminals
Series	150181
Application	Power, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	EconoLatch Wire-to-Wire Interconnects
Product Name	EconoLatch
UPC	889056491112

Physical

Durability (mating cycles max)	25
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.145/g
Packaging Type	Reel
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.70-2.10mm
Wire Size AWG	16, 18
Wire Size mm ²	0.82-1.31


Electrical

Current - Maximum per Contact	11.5A
Voltage - Maximum	400V

Material Info

Reference - Drawing Numbers

Application Specification	1501760001-AS-000
Packaging Specification	PK-150180-001-000
Product Specification	1501760001-PS-000
Sales Drawing	SD-150181-0001-000
Test Summary	1501760001-TS-000

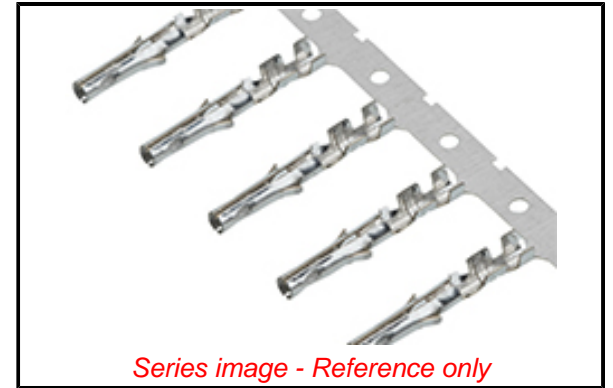

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[150181](#) Series

Use With

EconoLatch Receptacle Housing [150178](#) ,
[150179](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description **Product #**

Manual Extraction Tool [11030002](#)

Hand Crimp Tool for EconoLatch Male and Female Terminals, 16-18 AWG UL1061 and 18 AWG UL1007 wires FineAdjust Applicator [638280600](#) [639036100](#) for EconoLatch

Crimp Terminals,
16-18 AWG
FineAdjust Applicator [639036200](#)
for EconoLatch
Crimp Terminals, 18
AWG

This document was generated on 06/07/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION