

Data sheet

OpDAT REGplus for 6xSC-Duplex for crimp splice holder

Page 1/5

P/N

15024000010E

EAN 4250184117872


2022/11/11

Version: M

Illustrations



Dimensional drawing

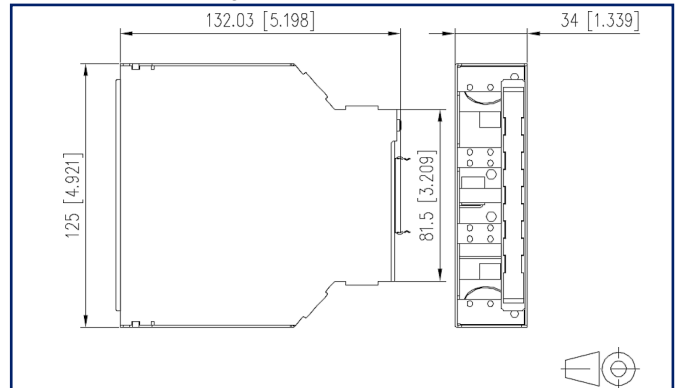

See enlarged drawings at the end of document

Product specification

- splice distributor for TH35 rail
- unequipped
- with fiber reservoir
- custom-labeled identification strips
- various mounting versions on rail
- splice tray with crimp splice holder for up to 12 splices / front plate can be completely removed
- cable feed from top or bottom, straight or inclined, with M20 cable gland (up to 2 possible)
- width: 34 mm (2HP), height: 125 mm, depth: 132.5 mm (from rail, without adapters)
- can be equipped with SC-D adapters
- feed of preassembled cables is possible
- one cable gland M20 with strain relief included in the delivery
- housing cover fastening by means of just one captive screw
- unoccupied adapter recesses can be closed with special blank covers
- blank cover 1x (860088-01), 2x (860088-02)
- variants: with crimp splice holder, with shrink splice holder
- please note: if you use preassembled cables with ST plugs, use the unequipped version of the OpDAT REG plus. The ST-D adapters required in this case are available as accessory. Before mounting the adapters in the housing, plug the preassembled ST plugs in the adapters for reasons of space.



P | Cabling

Data sheet

Page 2/5

OpDAT REGplus for 6xSC-Duplex for crimp splice holder

P/N
15024000010E
EAN 4250184117872
2022/11/11
Version: M

Technical Data

General Data

Fields of application	harsh environment
Mechanical measurement according to MICE	M1
Ingress measurement according to MICE	I1
Climatic measurement according to MICE	C1
Electromagnetic measurement according to MICE	E3
Design	patch panel
Color	gray
Dimensions	
Dimension (L x W x H)	132.03 mm x 125 mm x 34 mm
Dimension (L x W x H)	5.198 in. x 4.921 in. x 1.339 in.
Horizontal pitch	2HP
Labeling option	label strip / labeling strip

Connections/interfaces

Cable access/outlet	from top or bottom, straight or inclined
---------------------	--

Mechanical data

strain relief	PG gland
---------------	----------

Materials and material properties

Material - Strain relief	PA 6.6 UL94 V0
Material - Standard rail mounting support	Al (Aluminium)
RoHS	compliant

Classifications

ETIM 5.0	EC001130
ETIM 6.0	EC001130
ETIM 7.0	EC001130
ETIM 8.0	EC001130

Packing details

Type of packaging	1 pc(s) / box
Packaging unit - Weight (gram)	606 g

P | Cabling

Data sheet

Page 3/5

OpDAT REGplus for 6xSC-Duplex for crimp splice holder

P/N

15024000010E

EAN 4250184117872

2022/11/11

Version: M

Technical Data

Packing details

Packaging unit - Weight (pound)	1.34 lb
Packaging dimension	145 mm x 182 mm x 40 mm
Packaging dimension	5.709 in. x 7.165 in. x 1.575 in.

OpDAT REGplus for 6xSC-Duplex for crimp splice holder

P/N
15024000010E
EAN 4250184117872
2022/11/11
Version: M

Accessories

P/N	Designation
15090041-I	OpDAT ST-D Kupplung MM (Ph-Br, metallisch)
15090051-I	OpDAT ST-D adapter MM (ceramic, metallike)
15090052-30	OpDAT adapter SC-Duplex OM2 (metal) - 30 pieces
15090052-I	OpDAT adapter SC-Duplex OM2 (metal)
15090053-I	OpDAT ST-D/SC-D adapter MM (ceramic, metallike)
15090071-30	OpDAT adapter LC-Quad OS2 - 30 pieces
15090071-I	OpDAT adapter LC-Quad OS2
15090072-I	OpDAT LC-Q Kupplung MM (Ph-Br, beige)
15090078-30	OpDAT adapter LC-Quad OM3 - 30 pieces
15090078-I	OpDAT adapter LC-Quad OM3
15090079-30	OpDAT adapter LC-Quad OM4 - 30 pieces
15090079-I	OpDAT adapter LC-Quad OM4
1509007A-30	OpDAT adapter LC-Quad APC OS2 - 30 pieces
1509007A-I	OpDAT adapter LC-Quad APC OS2
150900B2-30	OpDAT adapter SC-Duplex OM2 - 30 pieces
150900B2-I	OpDAT adapter SC-Duplex OM2
150900BA-30	OpDAT adapter SC-Duplex OM3 - 30 pieces
150900BA-I	OpDAT adapter SC-Duplex OM3
150900BB-30	OpDAT adapter SC-Duplex OM4 - 30 pieces
150900BB-I	OpDAT adapter SC-Duplex OM4
150900C2-I	OpDAT SC-D Kupplung MM (Ph-Br, metallisch)
150900C3-I	OpDAT SC-D/ST-D Kupplung MM (Ph-Br, metallisch)
150900D2-30	OpDAT SC-D adapter OS2 (metallike+blue) - 30 pieces
150900D2-I	OpDAT adapter SC-Duplex OS2 (metal)
150900D3-30	OpDAT adapter ST/SC-Duplex OS2 - 30 pieces
150900D3-I	OpDAT adapter ST/SC-Duplex OS2
150900D4-30	OpDAT SC-D APC adapter OS2 (metallike+green)- 30 pieces
150900D4-I	OpDAT SC-D APC adapter OS2 (metallike+green)
150900E2-30	OpDAT adapter SC-Duplex OS2 - 30 pieces
150900E2-I	OpDAT adapter SC-Duplex OS2
150900F2-30	OpDAT adapter SC-Duplex APC OS2 - 30 pieces
150900F2-I	OpDAT adapter SC-Duplex APC OS2
899789-01	Label sheet for E-DAT C6 and E-DAT design patch panels

P | Cabling

Data sheet

OpDAT REGplus for 6xSC-Duplex for crimp splice holder

Page 5/5

P/N

15024000010E

EAN 4250184117872

2022/11/11

Version: M

Illustrations

Dimensional drawing

