


Coaxial Cable Connector 16_MM CX-50-2-4/111_O

Description

Right angle cable plug

Interface standards
SUHNER-MM CX

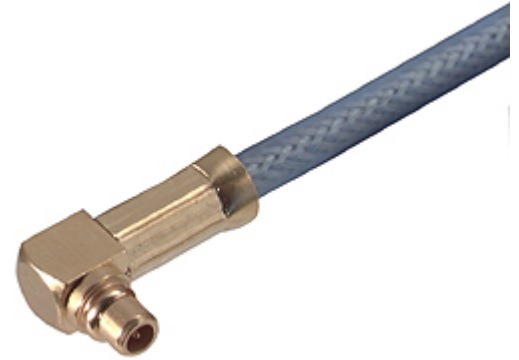

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0009 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU, RoHS	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (without Nickel underplating)
Body	Brass	Gold Plating (without Nickel underplating)
Insulator	PFA / PTFE	
Crimp ferrule	Copper	Gold Plating (without Nickel underplating)

Related Documents

Outline drawing	DOU-00006003
Catalogue drawing	DOU-00006005
Assembly instruction	DOC-0000241539

Ordering Information

Bulk 100 pcs package	16_MM CX-50-2-4/111_OH
Single package	16_MM CX-50-2-4/111_OE

Additional Information

Suitable cables	RG_316_U, ENVIROFLEX_316, RG_188_A/U, RG_174_U
-----------------	--