

Datasheet

RS Pro Slotted Screwdrivers (Cabinet Tip)


EN



Product feature:

DIN ISO 2380-1/2, ISO 2380-1

- Cabinet tip ideal for terminals
- Chrome Vanadium Molybdenum steel blade
- Matt chrome finish (black tip)
- Softgrip handle

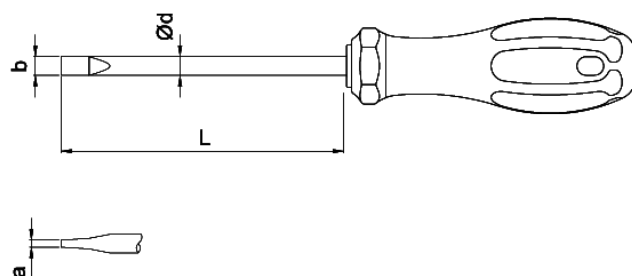

RS CODE NO	CODE NO	b mm	a mm	Ød mm	L mm	mm	gr
1829658	F10-025-075RS	2.5	0.4	2.5	75	90	35
1829659	F10-030-075RS	3.0	0.5	3.0	75	90	37
1829660	F10-030-100RS	3.0	0.5	3.0	100	90	38
1829661	F10-035-100RS	3.5	0.6	3.5	100	90	40
1829662	F10-040-075RS	4.0	0.8	4.0	75	100	53
1829663	F10-040-100RS	4.0	0.8	4.0	100	100	55
1829664	F10-040-125RS	4.0	0.8	4.0	125	100	58
1829665	F10-040-150RS	4.0	0.8	4.0	150	100	60
1829666	F10-055-100RS	5.5	1.0	5.0	100	100	64
1829667	F10-055-125RS	5.5	1.0	5.0	125	100	68
1829668	F10-055-150RS	5.5	1.0	5.0	150	100	72
1829669	F10-055-200RS	5.5	1.0	5.0	200	100	76