



Datasheet

Stock No. 190-2859, 190-2860, 190-2861, 190-2865,
190-2866, 190-2867

 









ENGLISH

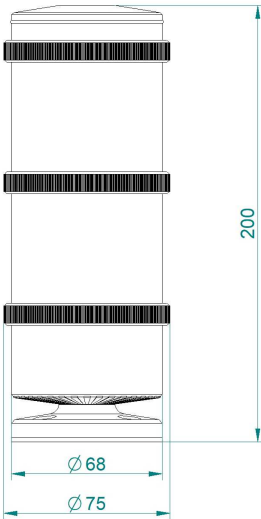
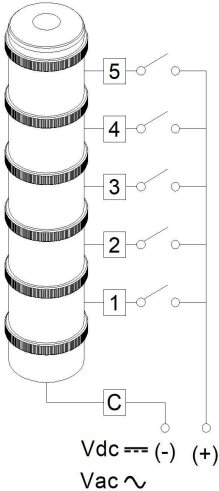
RS PRO EFFECT LIGHT TOWER 2 COLOUR



Luminous warning STACK LIGHT

BODY	PC										
RING	PC										
LUMINOUS SOURCE	N°12 LED										
AVAILABLE COLOURS	 										
VOLTAGE	24 Vdc/Vac – 110 Vac – 240 Vac										
OPERATION	∞										
CURRENT CONSUMPTION	<table border="1"> <thead> <tr> <th></th> <th>24Vdc</th> <th>24Vac</th> <th>110Vac</th> <th>240Vac</th> </tr> </thead> <tbody> <tr> <td>mA (max)</td> <td>130</td> <td>170</td> <td>70</td> <td>70</td> </tr> </tbody> </table>		24Vdc	24Vac	110Vac	240Vac	mA (max)	130	170	70	70
	24Vdc	24Vac	110Vac	240Vac							
mA (max)	130	170	70	70							
LIGHT OUTPUT	<table border="1"> <thead> <tr> <th></th> <th></th> <th></th> </tr> </thead> <tbody> <tr> <td>ALL COLOR Cd(p)</td> <td>7</td> <td>3</td> </tr> </tbody> </table>				ALL COLOR Cd(p)	7	3				
											
ALL COLOR Cd(p)	7	3									
LIGHT EFFECT	Fissa – 1F – 2F – 3F Steady – 1F – 2F – 3F Fixe – 1F – 2F – 3F Dauerlicht – 1F – 2F – 3F Luz fija – 1F – 2F – 3F										

These data are disclosed only for information purposes. RS Components reserves the right to modify them at any time without prior notice.

<p>IP RATING</p>	<p>IP66</p>
<p>OPERATING TEMPERATURE</p>	<p>-30°C+50°C</p>
<p>VIBRATIONS</p>	<p>INDUSTRIAL CEI 60068-2-6 SINE</p>
<p>CERTIFICATIONS, APPROVALS</p>	<p>CE</p>
<p>MOUNTING</p>	<p>Ring</p>
<p>TECHNICAL DRAWING</p>	
<p>ELECTRICAL WIRING</p>	



ENGLISH

Article Number

Specifications

1902859	70mm steady light tower RED + GREEN 24VAC/DC
1902860	70mm steady light tower RED + GREEN 110VAC
1902861	70mm steady colour light tower RED + GREEN 240VAC
1902865	70mm multi-effect light tower RED + GREEN 24VAC/DC
1902866	70mm multi-effect light tower RED + GREEN 110VAC
1902867	70mm multi-effect light tower RED + GREEN 240VAC