


ROLINE PDU for Cabinet, 8x socket, 45°, 16A, with Switch, black, 2 m

Product No.	19.07.1619
Manufacturer	ROLINE
Manufacturer No.	19.07.1619
EAN (single piece)	7630049627024

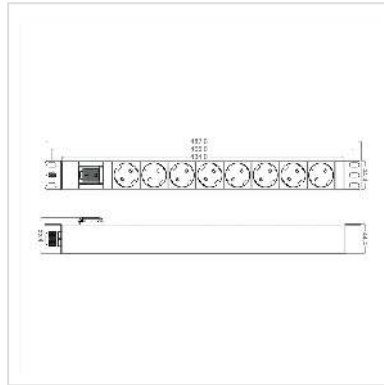

19" PDU with switch, 1U for installation in 19" racks, incl. installation brackets.

- 19" socket (1U) for installation in 19" cabinets, incl. installation angle
- Arrangement of sockets: 45°
- Profile of anodized aluminum
- Lighted switch
- Mounting length: 466 mm
- Product size: 487 x 44.4 x 44.4 mm

- Cable type: 2.0m H05VV-F 3G 1,50mm², black
- Max load/power: 16A 3600W
- Color: black
- Width: 487mm

Technical specifications

Manufacturer	ROLINE
Product group	Power Bars
Product type	19" power strip
Colour	black
Length	2 m
Function	19" Socket
Mounting form	19" Rackmount

Max. capacitance	3600W
Max. voltage	250V AC
ON/OFF Switch	yes
Number of socket pots	8
Quantity of outputs/angles	8 / 45°
Output alignment	Line
Socket type	3P. German, CEE 7/3
Material (casing)	Aluminium
Colour (Design profile)	black
Connection cable	H05VV-F 3G 1,5mm ²
Connector plug	CEE 7/7 German Type
Plug type	3P. German, CEE 7/7
Regional use	Germany, Austria, Netherlands
Height	44 mm
Width	487 mm
Depth	44 mm
Weight	834 g
Height of packaging (single piece)	110 mm
Width of packaging (single piece)	50 mm
Depth of packaging (single piece)	210 mm
Package weight (single piece)	0.95 kg