



ENGLISH

Datasheet

RS PRO 4 AND 8 POLE AUDIO CONNECTORS

Stock No: 2080625



4 Pole plug with PVC Cable
Grommet Blue nut is standard.
Dimensions: 29 x 28 x 93mm
Part No. RS1245



4 Pole plug without PVC Cable
Grommet Blue nut is standard.
Dimensions: 29 x 28 x 68mm
Part No. RS1250



4 Pole Cable Socket with PVC
Cable Grommet. Blue nut is
standard. Dimensions: 28 x 28 x
93mm **Part No. RS1255**

Plug Specification

Maximum Current: 20A.

Withstanding Voltage: $\geq 1400V$

Insulation Resistance: $\geq 1G\Omega$

Contact Resistance: $\leq 3m\Omega$

Solderability: $\leq 3S$


Insertion Force: 10-80N Minimum

Life: ≥ 2000


rspro.com




4 Pole Chassis Socket
 Compatible with all previous 4 Pole
 Plugs Dimensions: 24 x 24 x 33mm
Part No: **RS1270** with CSK Hole
RS1270X with Plain Hole

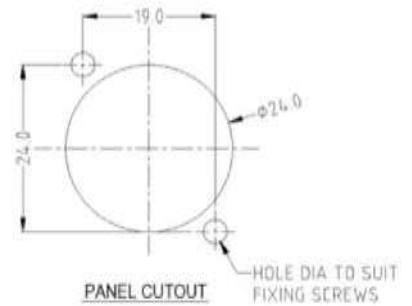

4 Pole Chassis Socket (Large Square
 Type) Compatible with all previous 4 Pole
 Plugs Dimensions: 40 x 40 x 33mm
Part No: **RS1275**

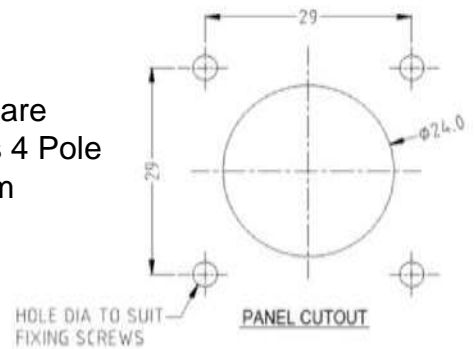

4 Pole Chassis Socket (Round Type)
 Compatible with all previous 4 Pole
 Plugs Dimensions: 50 x 50 x 33mm
Part No: **RS1280**

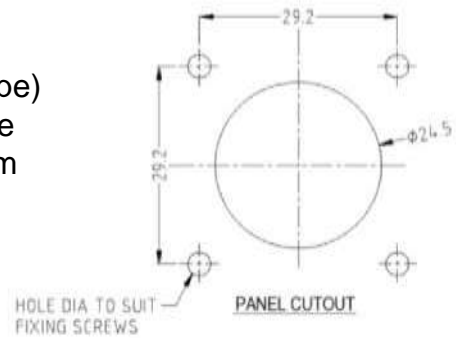

8 Pole Chassis Socket (Round
 Type) Dimensions: 51 x 51 x 33mm
Part No: **RS1285**

