

Datasheet

RS PRO UL1569 Red, 0.51 mm² Hook Up Wire, 305m

Stock No: 1242788



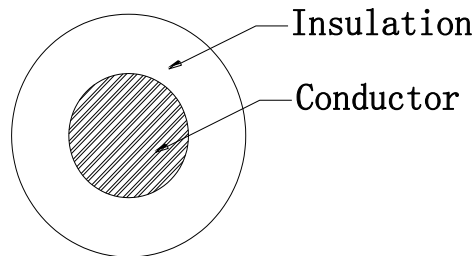
Technical Specifications:



Conductor	Tinned Copper
Cores Number	1C
Size(AWG)	20AWG
Construction(±0.008mm)	10/0.25
Stranded Dia.(mm)	0.93
Insulation Material	PVC
Insulation Color	Red (RAL3018)
Ave Thickness(mm)	0.40
Min Thickness(mm)	0.33
Insulation Dia.(±0.10mm)	1.75

Features & Benefits:

- **Temperature Range: -40 to 105 °C**
- **Conductor resistance(20°C Ω/km): 37.4Max.**
- **Insulation DC Resistance(20°C MΩ*Km): 200Min.**
- **Rated Voltage: 300V**

Cross Section drawings



Cable Marking: E254881  AWM STYLE 1569 20AWG
105°C 300V VW-1 C  AWM I A 105°C 300V FT1 -LF-
ELETECK

Applications: Hook up wire can be used for a broad range of applications, whether that be in a control cabinet, high-temperature oven, or in a specialised machine tool.