


D-Sub Connectors

DM-Series – Solder Cup


Insulator:	Glass filled Polyester, UL94 V-0
Colour:	Black or White
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy, Machined
Contact Plating:	Selective Gold over Nickel 500 inserts min.



Plug connector

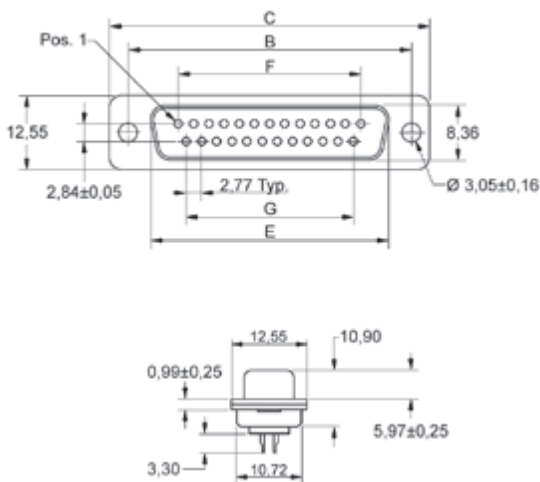

Socket connector

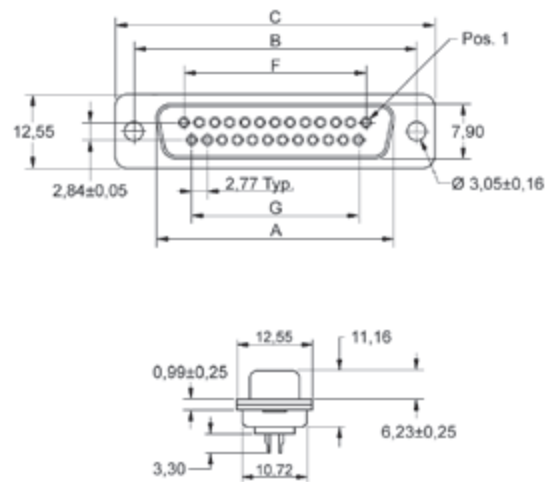

Size	A	B	C	E	F	G
9	16,92	24,99	30,81	16,33	11,08	8,31
15	25,25	33,32	39,14	24,66	19,39	16,62
25	38,96	47,04	53,04	38,38	33,24	30,47
37	55,25	63,50	69,32	54,84	49,86	47,09
50	Available on request					

Order Codes - Standard Type - with Ø 3.05mm Through Hole

BLACK INSULATOR

Option X (Standard)

Ø 3.05mm Holes



Plug Connector

09	2101-0200-01	DM09-SP
15	2101-0200-02	DM15-SP
25	2101-0200-03	DM25-SP
37	2101-0200-04	DM37-SP
50	2101-0200-05	DM50-SP

Socket Connector

09	2101-0200-11	DM09-SS
15	2101-0200-12	DM15-SS
25	2101-0200-13	DM25-SS
37	2101-0200-14	DM37-SS
50	2101-0200-15	DM50-SS

Order Codes - Standard Type - with Ø 3.05mm Through Hole

WHITE INSULATOR

Option X (Standard)

Ø 3.05mm Holes



Plug Connector

09	2108-0200-01	DM09-SP-W
15	2108-0200-02	DM15-SP-W
25	2108-0200-03	DM25-SP-W
37	2108-0200-04	DM37-SP-W
50	2108-0200-05	DM50-SP-W

Socket Connector

09	2108-0200-11	DM09-SS-W
15	2108-0200-12	DM15-SS-W
25	2108-0200-13	DM25-SS-W
37	2108-0200-14	DM37-SS-W
50	2108-0200-15	DM50-SS-W



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden


Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com

D-Sub Connectors

Order Codes - Option K - Back Nut UNC 4-40

BLACK INSULATOR

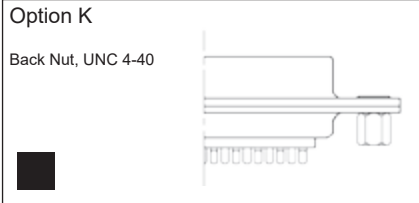


Plug Connector		
09	2101-0201-01	DM09-SP-K
15	2101-0201-02	DM15-SP-K
25	2101-0201-03	DM25-SP-K
37	2101-0201-04	DM37-SP-K
50	2101-0201-05	DM50-SP-K

Socket Connector		
09	2101-0201-11	DM09-SS-K
15	2101-0201-12	DM15-SS-K
25	2101-0201-13	DM25-SS-K
37	2101-0201-14	DM37-SS-K
50	2101-0201-15	DM50-SS-K

Order Codes - Option K - Back Nut UNC 4-40

WHITE INSULATOR

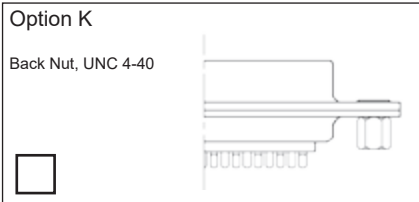


Plug Connector		
09	2108-0201-01	DM09-SP-W-K
15	2108-0201-02	DM15-SP-W-K
25	2108-0201-03	DM25-SP-W-K
37	2108-0201-04	DM37-SP-W-K
50	2108-0201-05	DM50-SP-W-K

Socket Connector		
09	2108-0201-11	DM09-SS-W-K
15	2108-0201-12	DM15-SS-W-K
25	2108-0201-13	DM25-SS-W-K
37	2108-0201-14	DM37-SS-W-K
50	2108-0201-15	DM50-SS-W-K

Order Codes - Option J - Front Nut UNC 4-40

BLACK INSULATOR

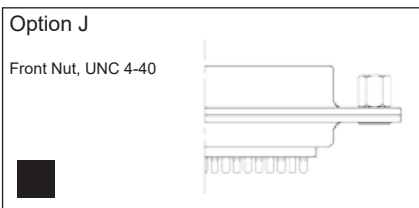


Plug Connector		
09	2101-0202-01	DM09-SP-J
15	2101-0202-02	DM15-SP-J
25	2101-0202-03	DM25-SP-J
37	2101-0202-04	DM37-SP-J
50	2101-0202-05	DM50-SP-J

Socket Connector		
09	2101-0202-11	DM09-SS-J
15	2101-0202-12	DM15-SS-J
25	2101-0202-13	DM25-SS-J
37	2101-0202-14	DM37-SS-J
50	2101-0202-15	DM50-SS-J

Order Codes - Option J - Front Nut UNC 4-40

WHITE INSULATOR

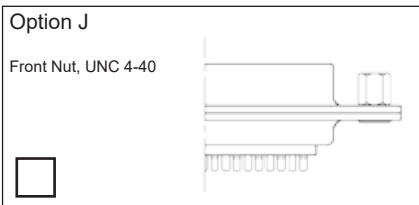


Plug Connector		
09	2108-0202-01	DM09-SP-J
15	2108-0202-02	DM15-SP-J
25	2108-0202-03	DM25-SP-J
37	2108-0202-04	DM37-SP-J
50	2108-0202-05	DM50-SP-J

Socket Connector		
09	2108-0202-11	DM09-SS-J
15	2108-0202-12	DM15-SS-J
25	2108-0202-13	DM25-SS-J
37	2108-0202-14	DM37-SS-J
50	2108-0202-15	DM50-SS-J

Order Codes - Option KJ - Back Nut + Screw Nut UNC 4-40

BLACK INSULATOR

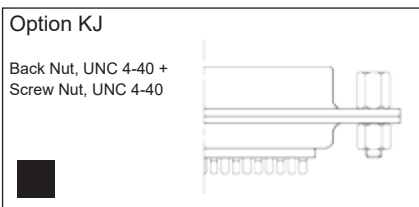


Plug Connector		
09	2101-0203-01	DM09-SP-KJ
15	2101-0203-02	DM15-SP-KJ
25	2101-0203-03	DM25-SP-KJ
37	2101-0203-04	DM37-SP-KJ
50	2101-0203-05	DM50-SP-KJ

Socket Connector		
09	2101-0203-11	DM09-SS-KJ
15	2101-0203-12	DM15-SS-KJ
25	2101-0203-13	DM25-SS-KJ
37	2101-0203-14	DM37-SS-KJ
50	2101-0203-15	DM50-SS-KJ

Order Codes - Option KJ - Back Nut + Screw Nut UNC 4-40

WHITE INSULATOR

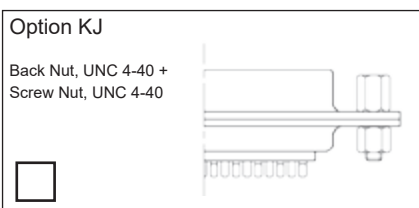

Plug Connector		
09	2108-0203-01	DM09-SP-KJ
15	2108-0203-02	DM15-SP-KJ
25	2108-0203-03	DM25-SP-KJ
37	2108-0203-04	DM37-SP-KJ
50	2108-0203-05	DM50-SP-KJ

Socket Connector		
09	2108-0203-11	DM09-SS-KJ
15	2108-0203-12	DM15-SS-KJ
25	2108-0203-13	DM25-SS-KJ
37	2108-0203-14	DM37-SS-KJ
50	2108-0203-15	DM50-SS-KJ

