

**Datasheet**

# RS PRO LED Twin Weatherproof – 5ft


Stock No: 2105501



<b>Model:</b>	<b>5' 55W 600mm Polycarbonate Weatherproof Twin IP65</b>
<b>Length</b>	<b>1500mm</b>
<b>Width</b>	<b>96mm</b>
<b>Height</b>	<b>83mm</b>
<b>Weight</b>	<b>13.6kg</b>

## Features & Benefits:

- Suitable for industrial and commercial applications
- Energy savings of up to 50%, compared to fluorescent fittings
- ENEC Approved Driver
- Wide Voltage range (100-240V), with built in low voltage protection device
- Operating temp of -25°C to +50°C
- Improved install design. 2-part fitting allows for quicker installation
- Supplied with tamper proof, stainless steel clips
- Compatible with besa box mounting.

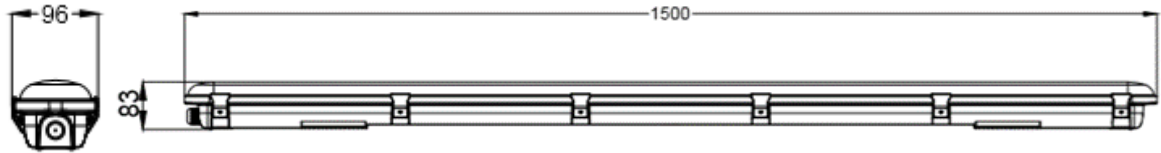

Model:	5' 55W 600mm Polycarbonate Weatherproof Twin IP65
Operating Wattage	55W
Operating Voltage	100-240V 50-60Hz
Power Factor	≥0.9
Colour Temperature	6500K
Luminous Flux	6600Lm
Luminous Efficiency	120Lm/W
CRI	≥80
Lifespan	50,000 Hrs
IP rating	IP65
IK Rating	IK08