


ROLINE S/FTP Patch Cord Cat.6 Component Level, LSOH, green, 0.3 m

Product No. 21.15.2954
Manufacturer ROLINE
Manufacturer No. 21.15.2954
EAN (single piece) 7611990135202

roline
Designed for Professionals

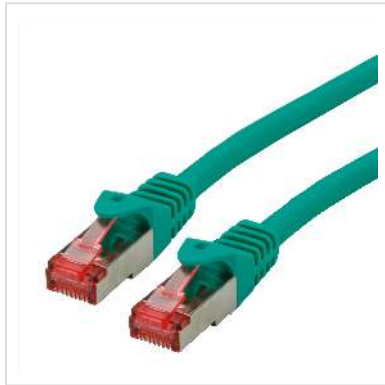

Cat.6
Class E

S/FTP

LSOH

COMPONENT
Level Tested

Patch cable for networking connections between devices. Prepared double shielded Twisted Pair cable with screened RJ-45 connectors on both ends. Durable due to moulded kink protection. Flexible cable, suitable for narrow bending. High quality plugs with gold plated contacts. Contact settings 1:1, in accordance with the EIA/TIA 568 standard. Construction: 4-pair stranded copper wire. Complete braid shielding. Pairs shielded with aluminium clad polyester foil. Halogen-free, flame retardant, low smoke.

100% Component Level testing

Technical specifications

Manufacturer	ROLINE
Product group	Twisted Pair Cable
Product type	S/FTP Patchcord
Colour	green
Length	0.3 m
Shield type	SFTP
Transfer quality	Cat6 / Class E

Component-Level certified	Yes
Impedance	100 Ohm
Quantity of wires	8
Conductor type	Wire
Crossed	No
Colour (Spout)	green
Cable LSOH	Yes
Side 1 Connector Type	RJ-45
Side 1 Connector Gender	Male
Side 2 Connector Type	RJ-45
Side 2 Connector Gender	Male
Connector Type RJ45	Standard
Weight	21.2 g
Height of packaging (single piece)	20 mm
Width of packaging (single piece)	140 mm
Depth of packaging (single piece)	140 mm
Package weight (single piece)	0.042 kg