


ROLINE FO SLIM Jumper Cable 50/125µm OM4, LSOH, LC/LC, OD 1.2mm, violet, 7 m

Product No.	21.15.9266
Manufacturer	ROLINE
Manufacturer No.	21.15.9266
EAN (single piece)	7630049620070

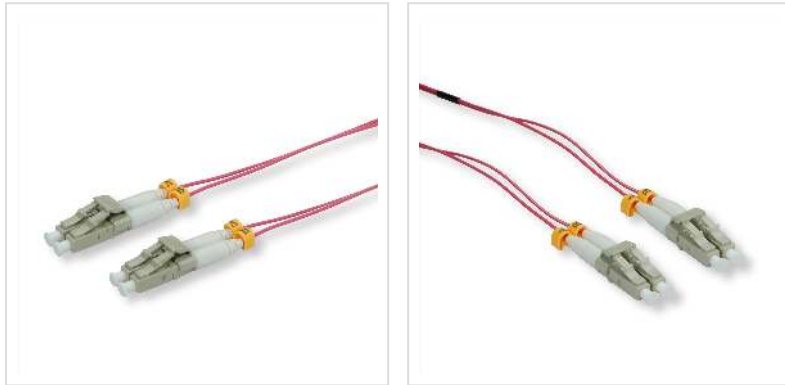

**The solution for space problems in the fiber optic area of your data center!
Extra-thin ROLINE fiber optic patch cables in OM4 quality for high-performance
fiber optic cabling in high-density environments.**

The LC connector with its small cross-section allows high densities in the distribution area. And thanks to the extra-thin cable with a straight 1.2mm diameter, we now also have the appropriate supplement to this connector.

- Security for the future! The OM4 fiber and connector quality with very low insertion ensure an excellent quality at very high bandwidths of up to 10 Gb/s Ethernet, Fibre Channel, and OIF applications to 550 meters - extends the system cost benefits to ultra long building backbones and medium length campus backbones.
- Material and clothing in ROLINE quality
- Outer diameter: 1.2 x 2.4mm
- UPC polish
- Modal Bandwidth: 4700 MHz-km (this bandwidth is based on application-specific implementation of the EMBC requirements)
- Duplex cables with fiber type Multi-mode 50/125µm, OM4

Technical specifications

Manufacturer	ROLINE
Product group	Fibre optic cable
Product type	Fibre Optic Jumper Cables OM4

Colour	violet
Length	7 m
Quantity of fibre	2
Conductor composition	Compact conductor
Cable type	Duplex Cable
External cable	No
Fibre section	50/125µm OM4
Connection ports	LC / LC
Side 1 Connector Type	LC
Side 2 Connector Type	LC
Aramid strain relief	Yes
External cable diameter	1.2 x 2.4 mm
Mantle of external cable	LS0H
Cable LSOH	Yes
Weight	24.8 g
Height of packaging (single piece)	20 mm
Width of packaging (single piece)	100 mm
Depth of packaging (single piece)	100 mm
Package weight (single piece)	0.02 kg