

Datasheet**Extra-low Voltage Mobile Industrial Plug**

Stock No:
2144092



Image for reference only


Technical Characteristics

Rated Current:	16
Rated Voltage	20-25
Poles	2P
Clock Position	0
Rated Frequency	50/60
Insulating Resistance	>10MΩ@500Vdc
Dielectric Stength	2,5kV 60s
IP Protection Degree	IP44 (IEC / EN 60529)
Operating Temperature	-25°C/ 40°C
Glow Wire Test	850°C live parts supports /650°C other parts
Material	Housing: PA6
Product Standard	IEC/EN 60309-1, IEC/EN 60309-2

Datasheet

Extra-low Voltage Mobile Industrial Plug

Stock No: 2144092

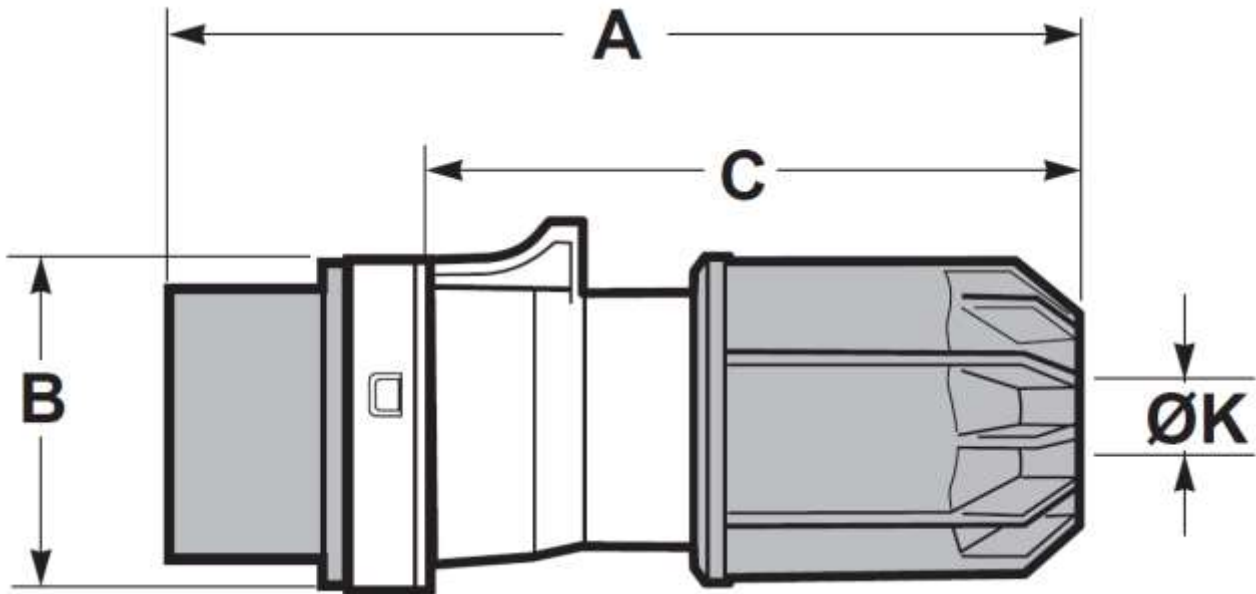

Dimensions in mm

A	B	C	D	E	F	G	ØK
135	51	110	-	-	-	-	9,5-24