

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2196572051](#)
Status: **Active**
Overview: [Pico-Lock Connector System](#)
Description: Pico-Lock Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 100.00mm Length, Gold (Au) Plating, 5 Circuits, Black

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	219657
Application	Power, Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	Pico-Lock-to-Pigtail
Overview	Pico-Lock Connector System
Product Name	Pico-Lock
Type	Discrete Wire Assembly
UPC	195842808584

Physical

Cable Length	100.00mm
Circuits (Loaded)	5
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Polyamide
Net Weight	4.301/g
Number of Rows	1
Pitch - Mating Interface	2.00mm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.20-1.50mm
Wire Size AWG	20
Wire/Cable Type	UL 10002


Electrical

Current - Maximum per Contact	3.5A
Voltage - Maximum	250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Sales Drawing	2196572050-000
---------------	----------------

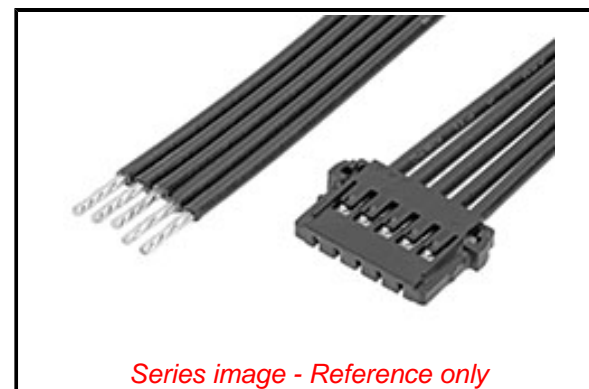

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[219657 Series](#)

Mates With

Pico-Lock PCB Header [205338](#)