



2220Z1 VB3™

The VB3™ 2220Z1 LED light has dual super bright white LEDs that may never need replacing and provide over 30 hours of run time. The light is ATEX safe for use in hazardous Zone 1 (Category 2) locations. The VB3™ 2220Z1 LED is ideal for professionals who work in areas with high risk of explosion such as chemical, pharmaceutical, power, oil and gas, and fire rescue.



DIMENSIONS

Length 3.50" (8.9 cm)

MATERIALS

Body Anti-static Impact Modified PC/PBT

Clip Anti-static Impact Modified PC/PBT

Contact Spring Retainer Stainless Steel

COLOURS

 High Visibility Yellow  Black

LIGHT SPECS

Lamp Type LED

POWER

Battery Size CR2032

Battery Type Lithium

Battery Quantity 2

Batteries Included yes

Volts 3.0v

WEIGHT

Weight With Batteries 1.0 oz (28 gr)

Weight Without Batteries 0.9 oz (26 gr)

Packaged Weight 1.7 oz (48 gr)

SWITCH

Switch Type Head Flip to Activate

Light Modes On / Off

CERTIFICATIONS



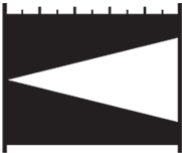


ATEX Zone 1

OTHER

Minimum Pack 6

Military yes

Package Code C

FL1 STANDARD	HIGH
	9 LUMENS
	34h 0mins
	12m
	38cd
	IPX4

Peli

c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999
info@peli.com • www.peli.com

Document created on 09-30-19