

FEATURES

- Simple to mount by screw
- Saddle design offers excellent stability
- Self-extinguishing UL 94 V-2
- Available in black and white
- Available in a range of sizes

RS PRO Black Cable Tie Mount 16mm x 23mm, 8mm Max. Cable Tie Width

RS Stock No.: 233-685



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Saddle style screw-mounted cable tie bases, available in black and white for outdoor and indoor use respectively. The clamps are manufactured from nylon 6.6 (also known as Nylon 66) that is classified to UL 94V-2, making them ideal for use where fire resistance is critical. Cable tie mounts have been designed specifically to be used with cables and wires to secure, identify and tidy cables.

General Specifications

Series	HC
Colour	Black
Material	Nylon 66
Minimum Operating Temperature	-45°C
Maximum Operating Temperature	+85°C
Quantity	250
Fire Behaviour	Self-Extinguishing
Fixation Method	Screw Mounting
Mounting Screw Type	Saddle
Application	Cable management and organisation

Mechanical Specifications


Length	23mm
Width	16mm
Fixing Hole Diameter	6.3mm
Cable Tie Width Acceptance	8mm

Approvals

Standards Met	UL 94V-2
----------------------	----------



Dimensions (mm)

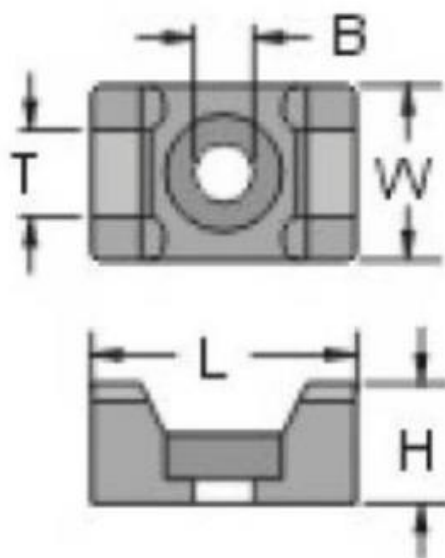

RS Stock No	H	L	W	T	B
666-717	7	15	10	5.1	3
666-739	9.8	23	16	9	6.3
233-663	7	15	10	5.1	3
233-685	9.8	23	16	9	6.3