



# Datasheet

## RS PRO 15m Cat6 UTP PVC Networking Cable - Grey

Stock number: 2406336

EN


The RS Pro range of CAT6 networking cables run at speeds up to 10/100/1000 which is commonly referred to as Gigabit networking speeds.

The internal conductors are made from 24awg 100% Full copper, have a PVC jacket and the outer diameter is 5.5mm. The connectors are RJ45 (8P8C) and the pins are gold plated to help prevent corrosion.

The wiring uses the ANSI/TIA-568B-C wiring which is standard for most networking uses.

The cables are UL certified to CM(UL) C(UL) E213738.


We have a wide variety of colours and lengths.

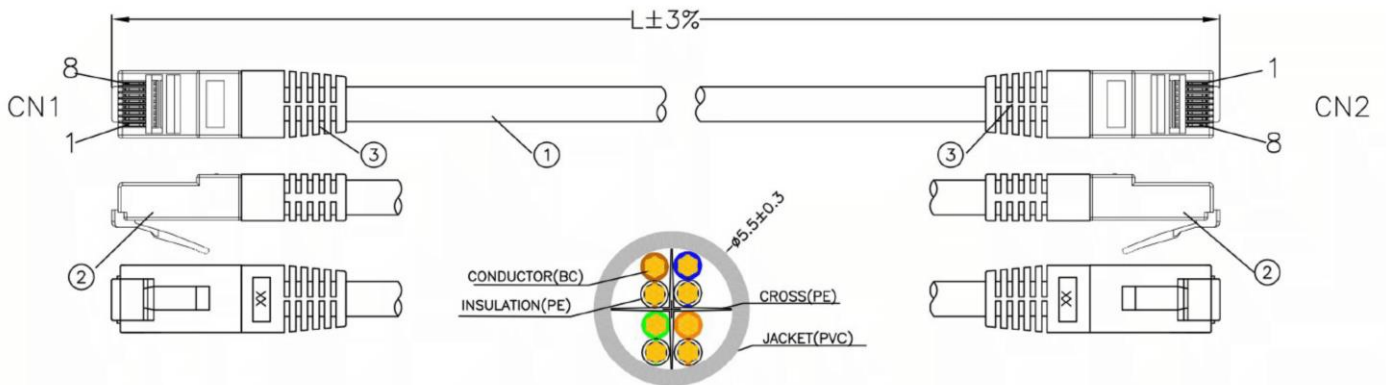

MATERIAL LIST:

NO	PARTS NAME	SPECIFICATION DESCRIPTION
①	CABLE	U/UTP [24AWG(BC 7/0.183±0.005)*1PR]*4+CROSS+PVC OD:5.5±0.2mm COLOR:Assorted upon request
②	RJ45 CONNECTOR	RJ45,8P8C,TWO FORK GOLD PLATED CONTACTS
③	MOLDING PVC	MOLDING PVC 45P COLOR:Assorted upon request

Marking: CM(UL) C(UL) E213738 4P 24AWG U/UTP CAT6 STRANDED PATCH ISO/IEC 11801 AND ANSI/TIA-568B-C.2

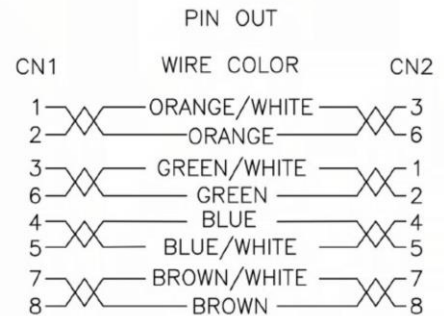

RoHS / REACH / CE / UKCA

[rspro.com](http://rspro.com)