


PCB HOLDER

25-304-0007

Product specifications

Material:	Conductive PS
Maximum temperature exposure:	60°C
Surface resistance:	10 ⁴ to 10 ⁶ Ohm
Slot Dimensions:	Width 3 mm Depth 8 mm

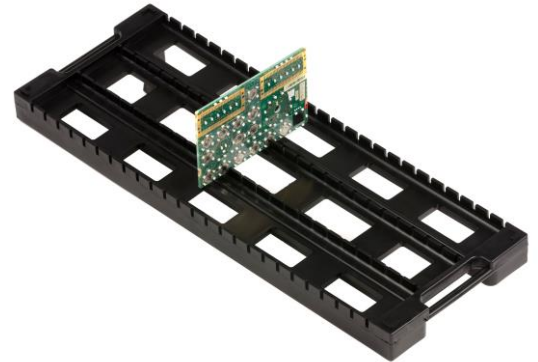

Strong construction from injection moulded plastic

Chemical resistance:

Alcohol:	Resistant
Aromatic hydrocarbons:	Severe attack
Aliphatic hydrocarbons:	Moderate attack
Concentrated acids:	Slight attack
Concentrated alkalines:	Slight attack
Dilute acids:	Resistant
Dilute alkalines:	Resistant
Kerosene:	Severe attack
Acetone:	Moderate attack
Mineral oil:	Slight attack
Oil and gasoline:	Moderate attack

Standard compliance: EN 61340-5-1

Sizes and Part Number

Part Number	External dimensions (mm)	Number of slots
25-304-0100	437 x 160 x 30	25