




FRONT

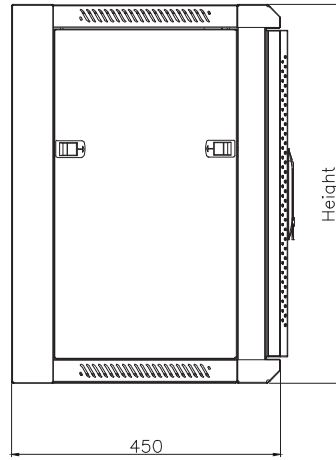


SIDE

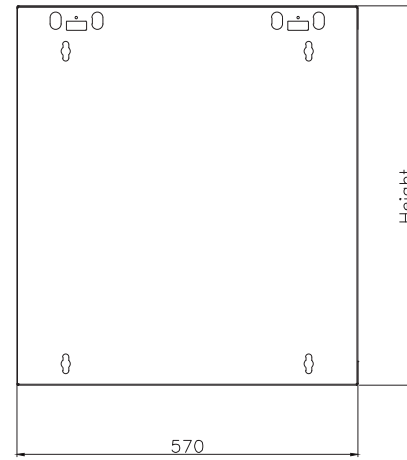


BACK

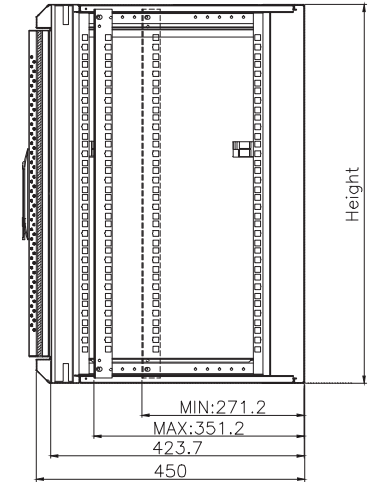

A-A

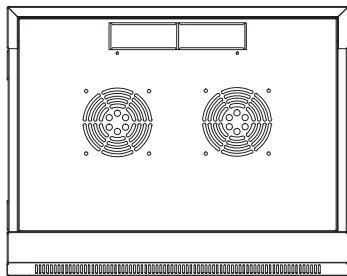

TOP

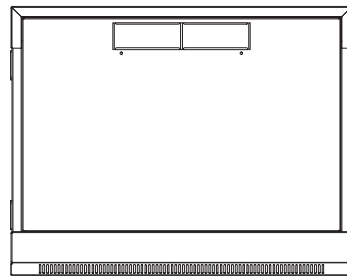

BOTTOM

Model No.	Capacity(U)	Height (mm)
SE5406■00	6	370
SE5409■00	9	500
SE5412■00	12	635
SE5415■00	15	770
SE5418■00	18	900

Standard:

Comply with ANSI/EIA RS-310-D、IEC60297-2、DIN41494;PART1; DIN41494;PART7

Material:

SPCC Cold Rolled Steel; rails: 1.2mm, others: 1.0mm

Loading capacity:

Static loading: 60KG

Feature:

- Flat packing and patent frame , packing time is less than 5 minutes , around 1/3~1/4 assembled original volume when flat pack
- Cable entry on both of top cover and bottom panel
- Steel front door , opening direction of door can be changed , turning angle of front door is over 180 degrees
- Different optional style of doors
- Wall mounted panel, convenience for installation , locked from inside with screw , avoiding to be stolen or accidentally dropped
- Flat side panel, easy installation
- Installation depth of mounting profile can be available changed
- 19"standard installation ;