


237A type 10 pair disconnection strip

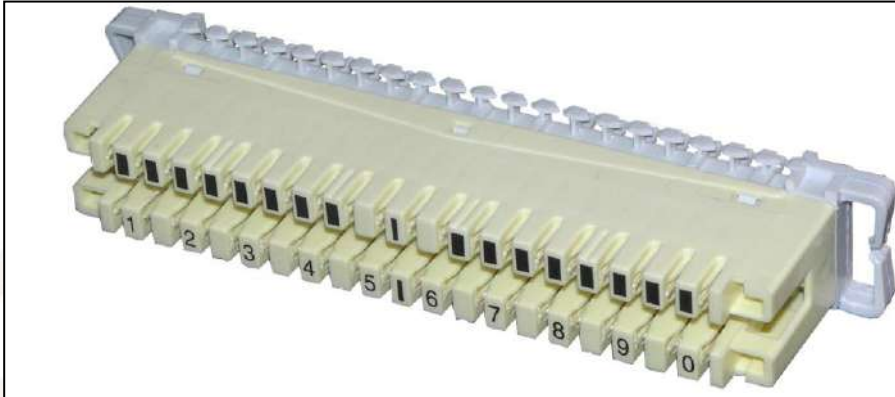

237A type 10 pair disconnection strip (27Aus)

This disconnection strip is our cost-effective 10 pair insulation displacement connection strip.

Features

- Fully compatible with industry standard back mount frames, insertion tools, connection boxes,
- UK OFTEL approved
- Industry standard LSA+ type contacts
- ISO 9001 approved manufacturing

Specifications

- Dimensions: 123mm x 20.5mm x 39.5mm
- Base: Polycarbonate
- Housing: PBT
- Both housing and base UL-94-V0 standard fire retardant
- Contacts: Silver plated Phosphor Bronze
- Wire connections per slot: 2