

Energy storage - QUINT-BAT/24DC/ 3.4AH - 2866349

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Energy storage device, lead AGM, VRLA technology, 24 V DC, 3.4 Ah. Connection via pin cable lug, 14 mm.

Product Description

QUINT-BAT – energy storage with lead AGM technology for maximum buffer times.



Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 959746
GTIN	4017918959746
Weight per Piece (excluding packing)	4,680.000 g
Custom tariff number	85072080
Country of origin	China

Technical data

Dimensions

Width	112 mm
Height	145 mm
Depth	123 mm

Ambient conditions

Degree of protection	IP20
Ambient temperature (operation)	0 °C ... 40 °C

Input data

Nominal input voltage	24 V DC
-----------------------	---------

Energy storage - QUINT-BAT/24DC/ 3.4AH - 2866349

Technical data

Output data

Nominal output voltage	24 V DC
Output current I_{max}	25 A
Connection in parallel	Yes, for increasing the buffer period
Connection in series	No
Output fuse	1x 25 A

General

IQ technology	no
Net weight	3.5 kg
Memory medium	battery 3.4 Ah
Degree of protection	IP20

Conformance/approvals

Shipbuilding approval	DNV GL (EMC A), ABS
-----------------------	---------------------


Environmental Product Compliance

	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 3
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Energy storage - QUINT-BAT/24DC/ 3.4AH - 2866349

Block diagram

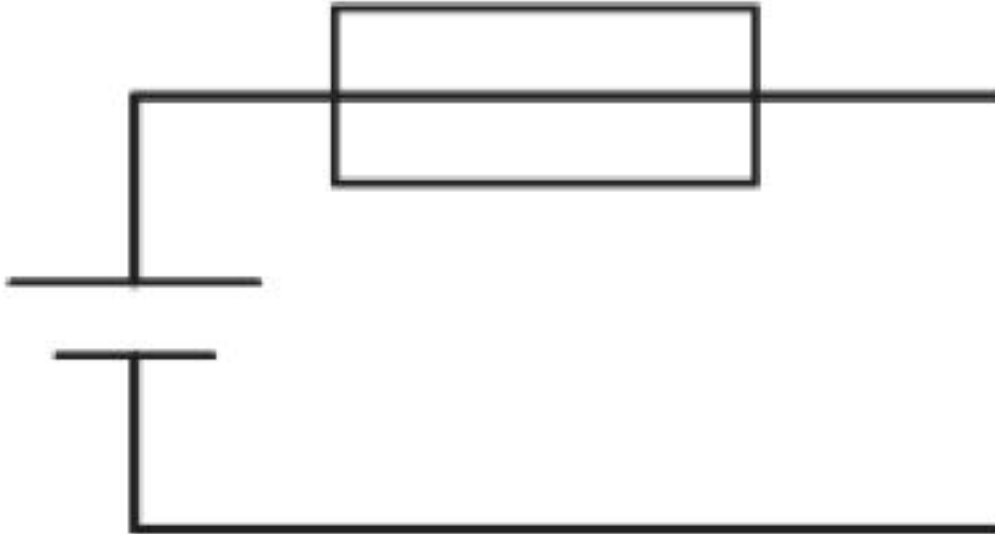

Classifications

eCl@ss

eCl@ss 4.0	27040600
eCl@ss 4.1	27040600
eCl@ss 5.0	27040600
eCl@ss 5.1	27040600
eCl@ss 6.0	27040600
eCl@ss 7.0	27050403
eCl@ss 8.0	27050403
eCl@ss 9.0	27050403

ETIM

ETIM 2.0	EC000382
ETIM 3.0	EC000382
ETIM 4.0	EC000357
ETIM 5.0	EC000357
ETIM 6.0	EC000357
ETIM 7.0	EC000357

UNSPSC

UNSPSC 6.01	30211510
-------------	----------

Energy storage - QUINT-BAT/24DC/ 3.4AH - 2866349

Classifications

UNSPSC

UNSPSC 7.0901	39121011
UNSPSC 11	39121011
UNSPSC 12.01	39121011
UNSPSC 13.2	26111715

Approvals

Approvals

Approvals

ABS / GL / ABS / BSH / EAC / EAC

Ex Approvals

Approval details


ABS	http://www.eagle.org/eagleExternalPortalWEB/	15-HG1369922-PDA-DUB
-----	---	----------------------

GL	 https://approvalfinder.dnvgl.com/	20582-04 HH
----	---	-------------

ABS	http://www.eagle.org/eagleExternalPortalWEB/	15-HG1369922-PDA
-----	---	------------------

BSH	http://www.bsh.de/de/index.jsp	Nr. 581
-----	---	---------

EAC		EAC-Zulassung
-----	---	---------------

EAC		RU C-DE.A*30.B.01082
-----	---	----------------------

Accessories

Accessories

Energy storage - QUINT-BAT/24DC/ 3.4AH - 2866349

Accessories

Assembly adapter

Assembly adapters - QUINT-ADAPTER/4 - 2866857

Assembly adapter for QUINT-BAT/24DC... on 35mm rail



Battery unit

Uninterruptible power supply replacement battery - UPS-BAT-KIT-VRLA 2X12V/3,4AH - 2908233



Replacement battery for UPS-BAT/VRLA... energy storage

Fuse

Fuse - SI FORM C 25 A DIN 72581 - 0913757



Flat-type plug-in fuse, type C, color code: white, nominal current: 25 A