


Spotlight Accos

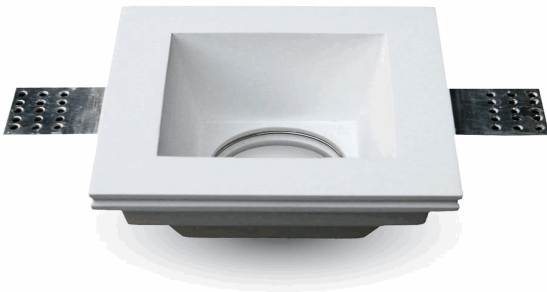

VT-763

HIGHLIGHTS :

WATTS



NA

LUMINOUS



NA

EQ. WATTS



NA

BEAM ANGLE



NA

Item No	: VT-763
SKU Code	: 3649
Watts	: NA
Base / holder	: GU10
Lumen(lm)	: NA
Beam Angle	: NA
Commercial type	: SQUARE
PF	: NA
LED Chip Type	: NA
CRI	: NA
Certification	: EMC,LVD,ROHS
IP Rating Protection Class	: IP20
Body type	: GYPSUM
Dimmable	: No
Life Time	: >20000 Hours
Operation Temperature	: -25 ~50°C
EAN code	: 3800157618595
Unit size	: 190 x 140 x 80mm
Cutting size	: 120 x 120mm
Packing details	: 0
Unit cbm	: 0

PRODUCT FEATURES

- Suitable for GU10 fitting Spotlights.
- Available in Stylish design, Shapes and colors.
- Body material-Die cast aluminum/Satin nickle.
- Upto 5 years Warranty.
- Easy to install.

[CLICK HERE](#)
FOR OTHER RELATED CERTIFICATES 