

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0369210503](#)
Status: **Active**
Overview: [L1NK Connector System](#)
Description: L1NK 396-to-L1NK 396 Off-the-Shelf (OTS) Cable Assembly, 3.96mm Pitch, Single Row, 300.00mm Length, 5 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	36921
Assembly Configuration	Dual Ended Connectors
Connector to Connector	L1NK 396-to-L1NK 396
Overmolded	No
Overview	L1NK Connector System
Product Name	L1NK 396
UPC	193264110803

Physical

Cable Length	300.00mm
Circuits (Loaded)	5
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	31.397/g
Packaging Type	Bag
Pitch - Mating Interface	3.96mm
Plating min - Mating	5.080µm
Plating min - Termination	5.080µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.12mm
Wire Size AWG	18
Wire/Cable Type	UL 1015


Electrical

Current - Maximum per Contact	13.0A
Voltage - Maximum	600V DC

Material Info

Reference - Drawing Numbers

Sales Drawing	369210500-000
---------------	---------------

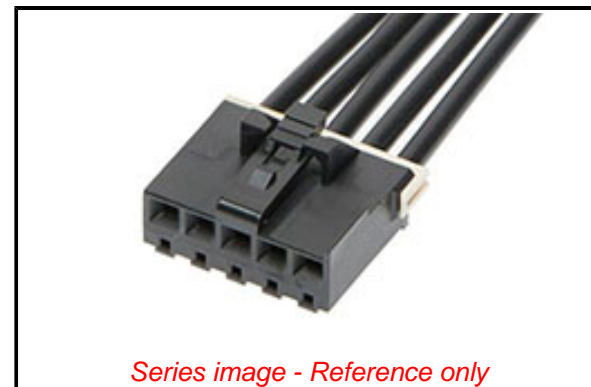

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[36921](#) Series

Mates With

L1NK 396 Headers [207478](#) , [207479](#)