

## Datasheet

# RS PRO KSA 0760 DIN tool for crimping red, blue and yellow pre-insulated terminals to DIN standard


Stock No: 399-2025




## Features & Benefits:

- High strength, through hardened alloy steel construction
- Unique mechanism significantly reduces hand force
- Versatile and easy to customize for right hand or left hand users.
- Non-slip pad holds tool in place when leveraging on a work surface
- Full cycle crimp mechanism to ensure consistent, reliable crimp
- Ratchet release mechanism to clear miss-crimps and obstructions
- Precision eccentric adjustment for consistent performance and ability to calibrate
- Hole in handle allows attachment of safety strap
- Each tool has a unique serial number for traceability

## Crimp Die Set

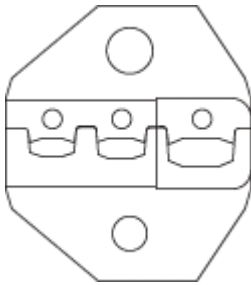

## Crimp Profile

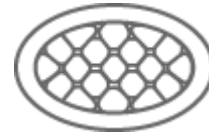

### TECHNICAL DATA

Length: 256 mm/10.08"

Width: 22 mm/0.87"

Height: 80 mm/3.15"

Weight: 559 gr/1.23 lb

Wire size: 0.75-6 mm<sup>2</sup> / AWG 22-AWG 10

Crimp dimensions mm/mm<sup>2</sup>:

0.5 – 1.0 mm<sup>2</sup> (red)/1.5 – 2.5 mm<sup>2</sup> (blue)/4 - 6 mm<sup>2</sup> (yellow)

Connector: Insulated terminals

Description: For German DIN standard pre insulated red, blue and yellow connectors.

Life span, cycles: 50,000