

SITOR CYLINDRICAL FUSE LINK AR 16 A, 600 V  
AC/400V DC



Figure similar

Model		
product brand name		SENTRON
General technical data		
Size of the fuse link		10x38 mm
Main circuit		
Operating voltage / Rated value	V	690
Operating current / Rated value	A	16
Product details		
Product component / striker		No
Net weight	g	6
Equipment marking		
<ul style="list-style-type: none"> <li>• acc. to DIN EN 61346-2</li> <li>• acc. to DIN EN 81346-2</li> </ul>		F F

General Product Approval

Declaration of Conformity



Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3NC1016>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<http://support.automation.siemens.com/WW/view/en/3NC1016/all>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NC1016](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1016)

**CAX-Online-Generator**

<http://www.siemens.com/cax>

**Tender specifications**

<http://ausschreibungstexte.siemens.com/tiplv>

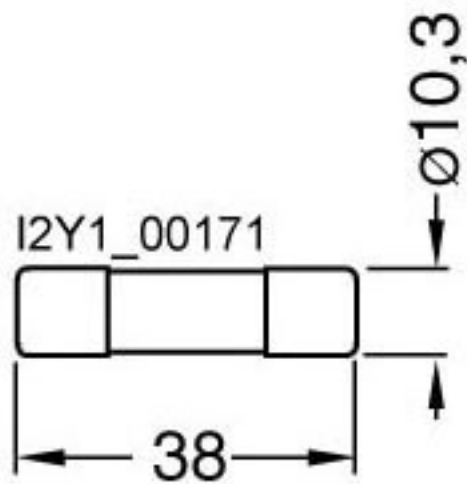

last modified:

05.05.2015