

---

# Product datasheet

## SPC.T OVEN CL 15 W 230 V E14

SPECIAL OVEN T | Incandescent lamps, tubular shape, for oven lighting

---

### Areas of application

- Domestic baking ovens



---

### Product features

- Ambient temperature: up to 300 °C



## Product datasheet

### Technical data

#### Electrical data

Nominal wattage	15.00 W
Nominal voltage	230 V
Rated wattage	15.00 W



#### Photometrical data

Luminous flux	85 lm
Color rendering index Ra	100
Color rendering index Ra	100

#### Light technical data

Starting time	0.0 s
Warm-up time (60 %)	0.00 s

#### Dimensions & weight

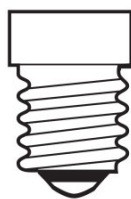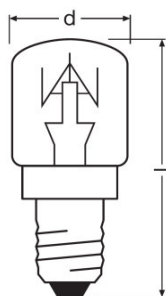

E14  
IEC 7004-23

Diameter	22.0 mm
Overall length	50.0 mm
Outer bulb	S22
Length	50.0 mm

#### Lifespan

Rated lamp life time	1000 h
Nominal lamp life time	1000 h

#### Additional product data

Base (standard designation)	E14
Mercury-free	Yes

## Product datasheet

Mercury content	0.0 mg
-----------------	--------

### Capabilities

Dimmable	Yes
----------	-----

### Certificates & standards

Energy efficiency class	E
Energy consumption	15 kWh/1000h

### Country specific categorizations

ILCOS	IBT/C-15-230-E14-22
-------	---------------------

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300003108	SPC.T OVEN CL 15 W 230 V E14	Shipping carton box 100 Pieces Folding carton box	308 mm x 149 mm x 228 mm	10.46 dm <sup>3</sup>	1510.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.

OSRAM GMBH is distribution partner  
of LEDVANCE for Digital Lighting  
Systems and Components

**OSRAM**

OSRAM GmbH  
Marcel-Breuer-Strasse 6  
80807 Munich, Germany