

PRODUCT DATASHEET

P CLAS A 60 8.5 W/4000K E27

PARATHOM CLASSIC A | LED lamps, classic bulb shape



AREAS OF APPLICATION

- Domestic applications
- General illumination
- Outdoor applications only in suitable luminaires

PRODUCT BENEFITS

- Low energy consumption
- Easy replacement of classic lamps thanks to compact design
- Instant 100 % light, no warm-up time

PRODUCT FEATURES

- LED alternative to conventional lamps
- Mercury-free lamps



TECHNICAL DATA

Electrical data

Rated wattage	8.50 W
Nominal wattage	8.50 W
Nominal voltage	220...240 V
Max. lamp no. on circuit break. 10 A (B)	149
Max. lamp no. on circuit break. 16 A (B)	240
Operating frequency	50...60 Hz
Power factor λ	> 0.50
Claimed equiv. conventional lamp power	60 W


Photometrical data

Nominal luminous flux	806 lm
Rated luminous flux	806 lm
Rated color temperature	4000 K
Lumen main.fact.at end of nom.life time	0.70
Light color (designation)	Cool White
Color temperature	4000 K
Luminous flux	806 lm
Color rendering index Ra	≥ 80
Standard deviation of color matching	≤ 6 sdc
Color rendering index Ra	≥ 80

Light technical data

Warm-up time (60 %)	< 0.50 s
Starting time	< 0.5 s

Dimensions & weight

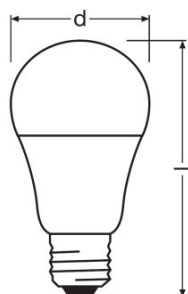

Overall length	112.0 mm
----------------	----------

Diameter	60.0 mm
Outer bulb	A60
Length	112.0 mm

Temperatures & operating conditions

Maximum temperature at tc test point	95 °C
---	-------

Lifespan

Nominal lamp life time	15000 h
Rated lamp life time	15000 h
Number of switching cycles	100000
Lumen maintenance at end of service life	0.70

Additional product data

Base (standard designation)	E27
Mercury content	0.0 mg
Mercury-free	Yes
Design / version	Frosted
Show WEEE picto	Yes
Product remark	All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value

Capabilities

Dimmable	No
-----------------	----


Certificates & standards

Energy efficiency class	A+
Energy consumption	9 kWh/1000h

Country-specific categorizations

ILCOS	DRAA/F-9/840-220-240-E27-60
Order reference	LEDPCLA60 8,5W/

Light Distribution

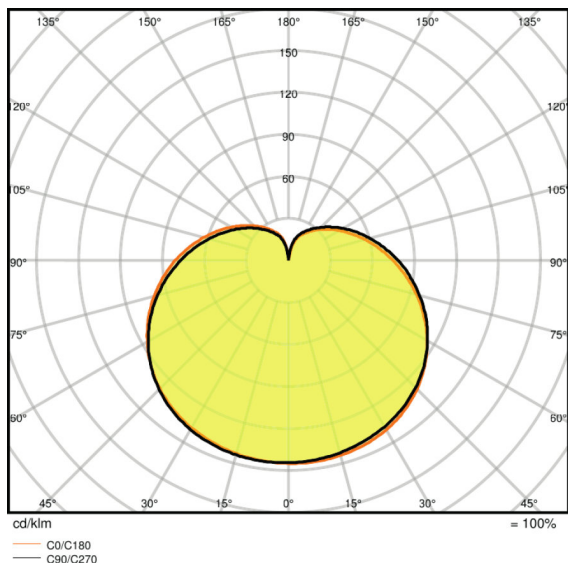

LDC typ polar

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075027077	Folding carton box 1	61 mm x 61 mm x 109 mm	52.00 g	0.41 dm ³
4058075027084	Shipping carton box 10	325 mm x 136 mm x 126 mm	624.00 g	5.57 dm ³
4058075292291	Folding carton box 1	60 mm x 60 mm x 111 mm	60.00 g	0.40 dm ³
4058075292307	Shipping carton box 10	325 mm x 136 mm x 126 mm	693.00 g	5.57 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

REFERENCES / LINKS

For further products and actual information concerning LED lamps see

- ▶ www.ledvance.com/ledlamps

For Guarantee see

- ▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.