


PSC 1,5/ 3-F


Order No.: 1841909

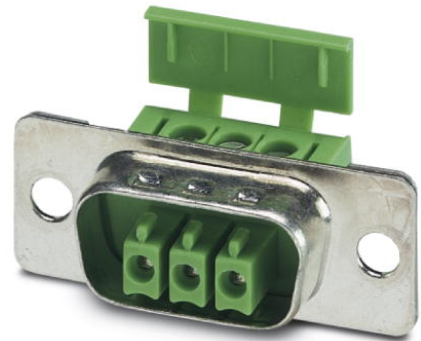

<http://eshop.phoenixcontact.se/phoenix/treeViewClick.do?UID=1841909>

Plug component, Nominal current: 8 A, Number of positions: 3, Pitch:
3.5 mm, Connection method: Screw connection, Color: green

Commercial data

EAN	 4 017918 105594
Pack	50
Customs tariff	85366990
Catalog page information	Page 301 (CC-2009)

Product notes

WEEE/RoHS-compliant since:
2003-01-01



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Dimensions / positions

Pitch	3.5 mm
Dimension a	7 mm
Number of positions	3
Screw thread	M2
Tightening torque, min	0.22 Nm
Tightening torque max	0.25 Nm

Technical data

Range of articles	PSC 1,5/..-F
Insulating material group	I
Connection in acc. with standard	EN-VDE
Nominal current I_N	8 A
Nominal voltage U_N	250 V (for applications in metal or metal-plated housings, the degree of protection "safety extra-low voltage" must be used.)
Nominal cross section	1.5 mm ²
Maximum load current	8 A
Insulating material	PA
Inflammability class acc. to UL 94	V0
Nominal voltage, UL/CUL Use Group B	300 V
Nominal current, UL/CUL Use Group B	8 A
Nominal voltage, UL/CUL Use Group D	300 V
Nominal current, UL/CUL Use Group D	8 A

Connection data

Conductor cross section solid min.	0.14 mm ²
Conductor cross section solid max.	1.5 mm ²
Conductor cross section stranded min.	0.14 mm ²
Conductor cross section stranded max.	1.5 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.25 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	1.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.25 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	1.5 mm ²
Conductor cross section AWG/kcmil min.	28
Conductor cross section AWG/kcmil max	16
Minimum AWG according to UL/CUL	30
Maximum AWG according to UL/CUL	14

Certificates

Certification CSA, CUL, GOST, UL

Accessories

Item	Designation	Description
------	-------------	-------------

Assembly

2749550	SCT-D-SUB 9-KG	POWER-SUBCON cable housing, 3-pos.
2749563	SCT-D-SUB 15-KG	POWER-SUBCON cable housing, 5-pos.

Tools

1205037	SZS 0,4X2,5 VDE	Screwdriver, bladed, VDE insulated, size: 0.4 x 2.5 x 80 mm, 2-component grip, with non-slip grip
---------	-----------------	---

Additional products


Item	Designation	Description
------	-------------	-------------

General


1841857	PSC 1,5/ 3-M	Header, Nominal current: 8 A, Number of positions: 3, Pitch: 3.5 mm, Color: green, Assembly: Soldering
1848122	PSC 1,5/ 3-M-PE	Header, Nominal current: 8 A, Number of positions: 3, Pitch: 3.5 mm, Color: green, Assembly: Soldering

Drawings

Dimensioned drawing

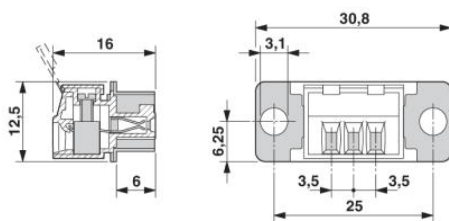

Schematic diagram

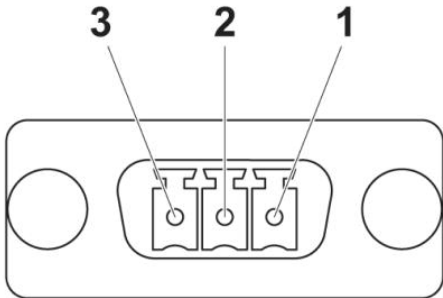

Address

Phoenix Contact AB
Linvägen 2
14144 Huddinge, Sweden
Phone +46 (0)8 - 608 64 00
Fax +46 (0)8 - 608 64 99
<http://www.phoenixcontact.se>

Phoenix Contact Oy
Technical modifications reserved;