

Actuator

46-
2C36.1M20.000



<https://eao.com/p/46-2C36.1M20.000>

Your product:



46-2C36.1M20.000 Actuator

FRONT

Front form:	round
Front dimension:	Ø 32 mm

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens illumination:	non illuminative
Lens material:	Plastic
Lens optics:	opaque
Lens colour:	Red
Lens shape:	mushroom-head

ELECTRICAL CHARACTERISTICS

Protection class:	II
--------------------------	----

MECHANICAL CHARACTERISTIC

Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Mechanical lifetime:	50 000 cycles of operation
Release type:	Twist to unlock
Weight:	0.034 kg

AMBIENT CONDITION


Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
IP front protection:	IP65
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IK front protection:	IK03
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Operating temperature:	- 25 °C ... + 55 °C

CERTIFICATE

Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850
Conformities:	CE
Approbations:	CSA, EAC, UL

OTHER

Housing colour:	Yellow
Short Description:	Actuator, Ø 22.3 mm, Ø 32 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, IP65, IK03, Twist to unlock
Housing material:	Plastic
Dimension:	Ø 32 mm
max. number of switching elements:	4
Dimension drawings:	

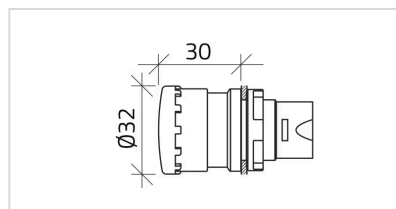

Mounting cut-outs:

