

Holder

46-
2V00.000.000



<https://eao.com/p/46-2V00.000.000>

Your product:



46-2V00.000.000 Holder

FRONT

Colour: Grey

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Weight: 0.016 kg

Tightening torque: 0.8 ... 1 Nm for screw terminal

AMBIENT CONDITION

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

IP front protection: IP20

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Operating temperature: - 25 °C ... + 55 °C

CERTIFICATE

Standards: CSA G22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508


Conformities: CE

Approbations: CSA, EAC, UL

OTHER

Colour RAL: 7016 RAL
Short Description: Holder, Plastic
Dimension: 38 mm x 30 mm
Material: Plastic

Dimension drawings:

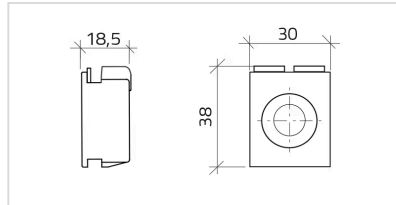

Wiring diagrams:

