

467BF - Metric hinged jointed combination wrenches





Standards:

NF ISO 1711-1, NF ISO 691, ISO 1711-1, ISO 691, DIN ISO 1711-1, DIN ISO 691

Description:

- Hinged head ratchet combination wrenches: to reach difficult access nuts.
- Compact ratchet mechanism and reversible by flipping the wrench.
- Increment 5° (6° for dimensions 8 and 9 mm).
- Ring head hinged at 180°.
- Open end head angled at 15°.
- Metric sizes: 8 to 19 mm.
- Presentation: satin chrome finish.

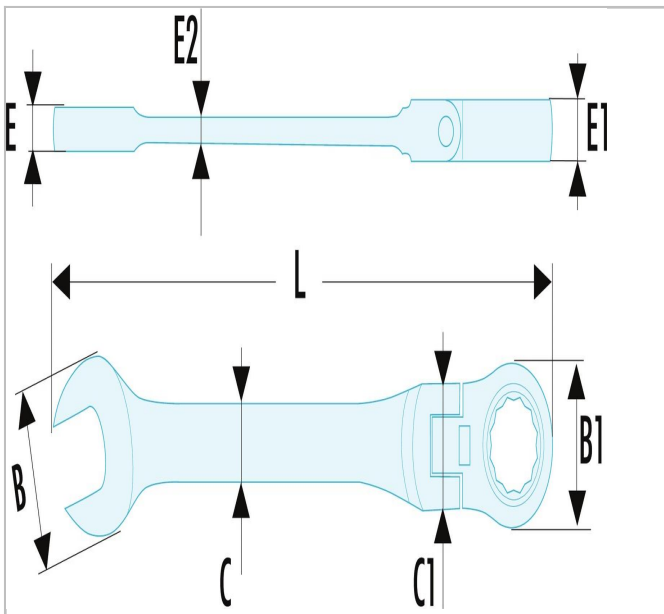

	A [mm]	Length L [mm]	Thickness E [mm]	Thickness E1 [mm]	Thickness E2 [mm]	Head Height C [mm]	Head Width B [mm]	Head Width B1 [mm]	Weight [Kg]
467BF.10	10.0	136.5	5.1	7.3	3.6	9.8	22.7	20.0	0.053
467BF.11	11.0	141.5	5.2	7.7	3.7	9.8	23.7	21.8	0.061
467BF.12	12.0	148.0	5.4	8.2	4.0	10.7	26.8	23.0	0.074
467BF.13	13.0	155.0	5.7	8.6	4.5	11.6	28.4	25.2	0.094
467BF.14	14.0	161.0	5.9	9.0	4.5	12.0	30.8	26.8	0.108
467BF.15	15.0	170.0	6.1	9.4	4.7	13.4	32.3	28.3	0.123
467BF.16	16.0	180.0	6.6	9.9	5.3	13.5	34.9	29.8	0.152
467BF.17	17.0	191.0	6.6	10.3	5.4	15.0	36.8	31.8	0.167
467BF.18	18.0	204.0	7.4	10.7	5.8	15.1	38.4	32.8	0.189
467BF.19	19.0	216.0	7.4	11.2	5.9	15.2	41.2	33.9	0.215
467BF.7	7								
467BF.8	8.0	127.5	4.6	6.5	3.1	8.0	18.6	16.7	0.038